



Vibration Free Gauges

Our exclusive encapsulated silicone dampened movement .

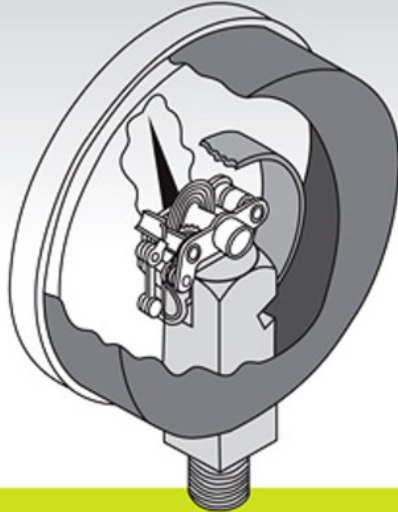

Competitors' Standard Gauge

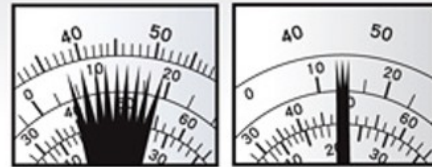

Vibration Free Gauges

- Provides steady and accurate pressure readings .
- Shock resistant movement seldom needs recalibration .
- Guaranteed not to LEAK FLUID .
- Guaranteed not to LOSE DAMPENING CHARACTERISTICS .

REFRIGERATION TOOLS

GAUGE 80mm >>>

Refrigerant	Compound	Pressure
R12, R22, R134a (°F)	RG-A250-VF	RG-A500-VF
R12, R22, R134a (°C)	RG-A250-VC	RG-A5000-VC
R134a (°F, °C)	RG-A134L-V	RG-A134H-V
R410a (°F, °C)	RG-A410L-V	RG-A410H-V
R404a, 407c, 507a, 134a (°C)	RG-A404L-VC	RG-A404H-VC



>>> GAUGE 70mm



Refrigerant	Compound	Pressure
R12, R22, R134a (°F)	RG-250-VF	RG-500-VF
R12, R22, R134a (°C)	RG-250-VC	RG-5000-VC
R134a (°F, °C)	RG-134L-V	RG-134H-V
R410a (°F, °C)	RG-410L-V	RG-410H-V
R404a, 407c, 507a, 134a (°C)	RG-404L-VC	RG-404H-VC



- To order manifold gauge sets with rubber protector, simply place "GP" after item number.