


チッコロ<sup>アルファ</sup> 7000シリーズ


1台で2機能を搭載 **ロック機構** + **開度指示機構**

**SW**  
両内ネジ型

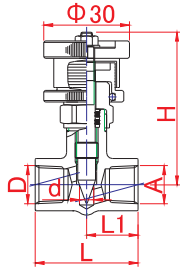


品番	φd	A (Rc)	D (Rc)	L1	L	H(約)
SW-7011	4.5	1/8	1/8	16	32	55
SW-7022	5	1/4	1/4	18	36	53
SW-7033	5	3/8	3/8	20	40	53

**SM**  
外・内ネジ型

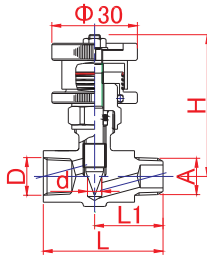

品番	φd	A (R)	D (Rc)	L1	L	H(約)
SM-7011	4.5	1/8	1/8	22	38	55
SM-7022	5	1/4	1/4	24	42	53
SM-7033	5	3/8	3/8	27	47	53

**SS**  
両外ネジ型

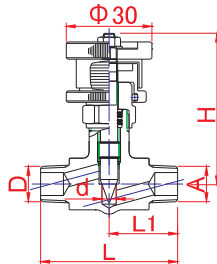


品番	φd	A (R)	D (R)	L1	L	H(約)
SS-7011	4.5	1/8	1/8	22	44	55
SS-7022	5	1/4	1/4	24	48	53
SS-7033	5	3/8	3/8	27	54	53

チッコロ<sup>アルファ</sup> 8000シリーズ

1台で3機能を搭載 **パネル取付機能** + **ロック機構** + **開度指示機構**


**SW**  
両内ネジ型

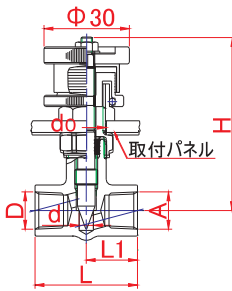

品番	φd	A (Rc)	D (Rc)	φdo	L1	L	H(約)
SW-8011	4.5	1/8	1/8	14	16	32	64
SW-8022	5	1/4	1/4	14	18	36	63
SW-8033	5	3/8	3/8	14	20	40	63

※φdoはパネルの穴径


**SM**  
外・内ネジ型

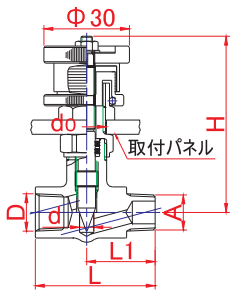

品番	φd	A (R)	D (Rc)	φdo	L1	L	H(約)
SM-8011	4.5	1/8	1/8	14	22	38	64
SM-8022	5	1/4	1/4	14	24	42	63
SM-8033	5	3/8	3/8	14	27	47	63

※φdoはパネルの穴径

**SS**  
両外ネジ型

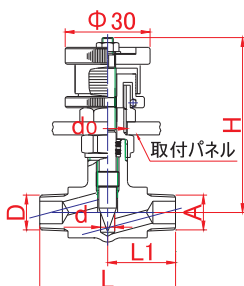

品番	φd	A (R)	D (R)	φdo	L1	L	H(約)
SS-8011	4.5	1/8	1/8	14	22	44	64
SS-8022	5	1/4	1/4	14	24	48	63
SS-8033	5	3/8	3/8	14	27	54	63

※φdoはパネルの穴径