


# Shock absorber


## ACA, ACJ Series

### ■ Dimensions

#### ACA

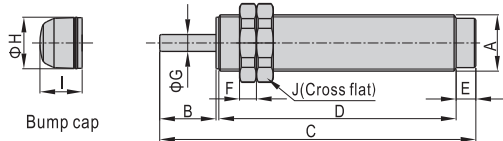


Model\Item	A	B	C	D	E	F	G	H	I	J
ACA0806	M8×1.0	6	45	31	5	4	3	6.5	6	11
ACA1007	M10×1.0	7	55	40	5	4	3	8.5	7.5	14
ACA1210	M12×1.0	10	62	46	5	4	3	10	7.5	17
ACA1215	M12×1.0	15	78	57	5	4	3	10	7.5	17
ACA1412	M14×1.5	12	80.5	62.5	5	6	4	12	12	19
ACA1416	M14×1.5	16	92.5	70.5	5	6	4	12	12	19
ACA1420	M14×1.5	20	103	77	5	6	4	12	12	19
ACA2020	M20×1.5	20	112.5	84.5	7	6	6	18	15	26
ACA2025	M20×1.5	25	122.5	89.5	7	6	6	18	15	26
ACA2030	M20×1.5	30	142	104	7	6	6	18	15	26
ACA2040	M20×1.5	40	167.5	119.5	7	6	6	18	15	26
ACA2525	M25×1.5	25	123	89	8	6	6	23	16	32
ACA2550	M25×1.5	50	183	124	8	6	6	23	16	32
ACA2725	M27×1.5	25	127	93	8	6	8	24.5	17	36
ACA2750	M27×1.5	50	192	133	8	6	8	24.5	17	36

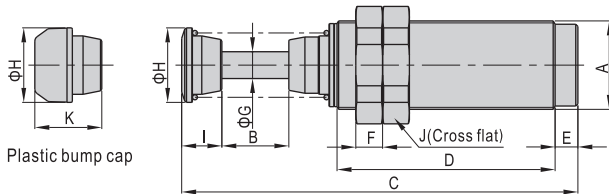


Model\Item	A	B	C	D	E	F	G	H	I	J	K
ACA3325	M33×1.5	25	148	81.5	8.5	10	10	27.8	15	41	25
ACA3350	M33×1.5	50	213	121.5	8.5	10	10	27.8	15	41	25
ACA3625	M36×1.5	25	148	81.5	8.5	10	10	27.8	15	46	25
ACA3650	M36×1.5	50	213	121.5	8.5	10	10	27.8	15	46	25

#### ACJ

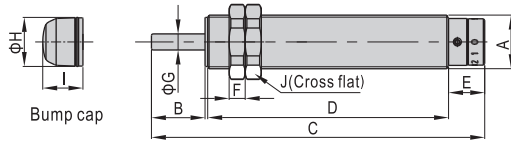


Model\Item	A	B	C	D	E	F	G	H	I	J
ACJ1007	M10×1.0	7	66	45	11	4	3	8.5	7.5	14
ACJ1210	M12×1.0	10	73	51	11	4	3	10	7.5	17
ACJ1412	M14×1.5	12	91	66.5	11.5	6	4	12	12	19
ACJ2020	M20×1.5	20	124.5	90	13.5	6	6	18	15	26
ACJ2525	M25×1.5	25	132.5	92	14.5	6	6	23	16	32
ACJ2550	M25×1.5	50	192.5	127	14.5	6	6	23	16	32
ACJ2725	M27×1.5	25	137	96.5	14.5	6	8	24.5	17	36
ACJ2750	M27×1.5	50	202	136.5	14.5	6	8	24.5	17	36

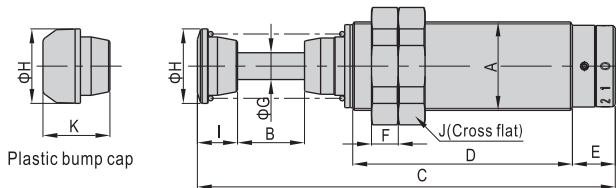

Model\Item	A	B	C	D	E	F	G	H	I	J	K
ACJ3325	M33×1.5	25	156	82	16	10	10	27.8	15	41	25
ACJ3350	M33×1.5	50	221	122	16	10	10	27.8	15	41	25
ACJ3625	M36×1.5	25	156	82	16	10	10	27.8	15	46	25
ACJ3650	M36×1.5	50	221	122	16	10	10	27.8	15	46	25
ACJ4225	M42×1.5	25	161.5	85.5	16	12	12	34.8	15	50	25
ACJ4250	M42×1.5	50	226.5	125.5	16	12	12	34.8	15	50	25
ACJ4275	M42×1.5	75	291.5	165.5	16	12	12	34.8	15	50	25

### ■ Accessories

#### How to set stop collar

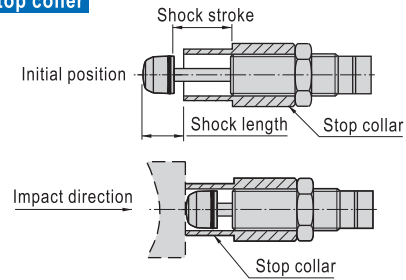


#### Ordering code


#### F-ACA 08 LM

Accessory	Accessories type
Model	Female thread size
	LM: Stop collar
	FA: Flange
	08: M8
	10: M10
	12: M12
	14: M14
	20: M20
	25: M25
	27: M27
	33: M33
	36: M36
	42: M42

#### Dimensions

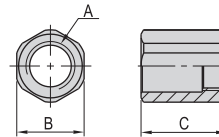


Model\Item	A	B	C
F-ACA08LM	M8×1.0	11	14
F-ACA10LM	M10×1.0	14	16
F-ACA12LM	M12×1.0	17	20

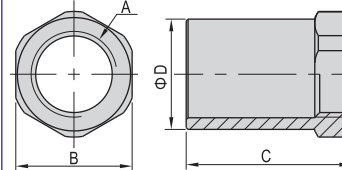


Model\Item	A	B	C	D
F-ACA14LM	M14×1.5	19	27	18
F-ACA20LM	M20×1.5	26	35	25
F-ACA25LM	M25×1.5	32	45	31
F-ACA27LM	M27×1.5	36	50	35
F-ACA33LM	M33×1.5	41	80	40
F-ACA36LM	M36×1.5	46	80	45

#### F-ACA36FA

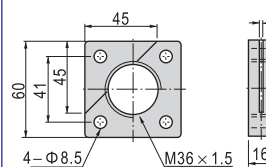

#### F-ACA42FA

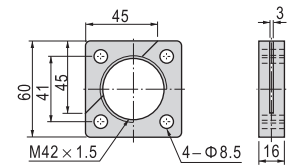

#### Selecting list

Model	Compatible absorber
F-ACA08LM	ACA0806
F-ACA10LM	ACA1007, ACJ1007
F-ACA12LM	ACA1210, ACA1215, ACJ1210
F-ACA14LM	ACA1412, ACA1416, ACA1420, ACJ1412
F-ACA20LM	ACA2020, ACA2025, ACA2030, ACA2040, ACJ2020
F-ACA25LM	ACA2525, ACA2550, ACJ2525, ACJ2550
F-ACA27LM	ACA2725, ACA2750, ACJ2725, ACJ2750
F-ACA33LM	ACA3325, ACA3350, ACJ3325, ACJ3350
F-ACA36LM	ACA3625, ACA3650, ACJ3625, ACJ3650
F-ACA36FA	ACA3625, ACA3650, ACJ3625, ACJ3650
F-ACA42FA	ACJ4225, ACJ4250, ACJ4275



Shock absorber

