



SBS 北川スクロールチャック用



■材質：S45C

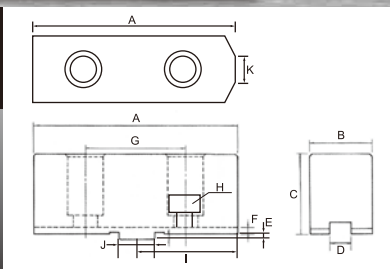

爪形状

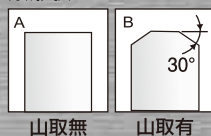

取付ボルト穴寸法

インチ	穴径(mm)
6	13.5
7	17
9	19
10	19
12	19

単位：mm

生爪型式		希望小売価格 (1set3個入/円税別)	A	B	C	D	E	F	G	H	I	J	K	爪形状	
SBS	6	H36	4,900	77	26	36	7.94	3	3.5	38.1	M8	41	12.68	-	A
		H60	8,000			60									
	6B	H32	4,500	73	26	32	7.94	3	3.5	38.1	M8	41	12.68	9	B
		H48	6,600			48									
		H73	10,000			73									
	7	H38	5,700	92	28	38	7.94	3	3.5	44.45	M10	48	12.68	-	A
		H60	9,600			60									
		H90	16,600			90									
	7B	H32	5,000	89	31	32	7.94	3	3.5	44.45	M10	49.7	12.68	9	B
		H48	7,700			48									
		H73	10,500			73									
		H100	17,000			100									
		H120	20,000			120									
	9	H45	6,600	100	32	45	12.7	3	3.5	53.98	M12	55	19.03	-	A
		H60	11,300			60									
		H90	17,400			90									
	9B	H32	6,000	103	31	32	12.7	3	3.5	53.98	M12	56	19.03	13	B
		H48	6,600			48									
		H63	11,300			63									
		H80	16,600			80									
H100		17,400	100												
H120		21,000	120												
10	H48	8,000	110	35	48	12.7	3	3.5	53.98	M12	60	19.03	-	A	
	H60	14,000			60										
	H90	19,100			90										
10B	H50	8,000	110	35	50	12.7	3	3.5	53.98	M12	60	19.03	13	B	
	H60	14,500			60										
	H75	17,000			75										
12	H51	10,100	125	40	51	12.7	3	3.5	63.5	M12	67.5	19.03	-	A	
	H90	20,800			90										
12B	H54	10,100	125	40	54	12.7	3	3.5	63.5	M12	67.25	19.03	13	B	
	H70	15,000			70										
	H90	20,800			90										
	H120	25,000			120										

※生爪兼用表は42ページを参照ください。

SBS長爪 北川スクロールチャック用

単位：mm



■材質：S45C

生爪型式				希望小売価格 (1set3個入/円税別)	A	B	C	D	E	F	G	H	I	J	爪形状
SBS	7	H48	L150	20,000	150	31	48	7.94	3	3.5	44.45	M10	110.8	12.68	A
	9	H48	L150	22,000	150	31	48	12.7	3	3.5	53.98	M12	103	19.03	A
	12	H48	L180	26,000	180	40	48	12.7	3	3.5	63.5	M12	122.3	19.03	A

※生爪兼用表42ページを参照ください。

生爪