


モルコジョイント


T

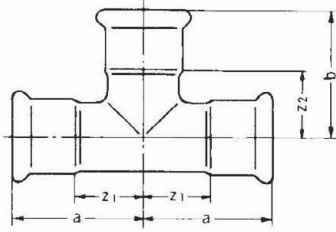

ティー

呼び径 (Su)	a	b	z1	z2	単価	ケース入数	袋入数
13	38	38	17	17	1,270	M160	10
20	46	46	22	22	1,600	M80	5
20×13	46	42	22	21	1,550	M80	5
25	51	51	27	27	1,970	M40	5
25×13	51	53	27	32	2,130	M40	5
25×20	51	51	27	27	1,950	M40	5
30	99	99	60	60	4,560	S10	1
30×13	99	67	60	46	5,510	S10	1
30×20	99	70	60	46	5,500	S10	1
30×25	99	70	60	46	5,310	S10	1
40	107	107	60	60	6,840	M10	1
40×13	107	69	60	48	8,000	M10	1
40×20	107	72	60	48	7,590	M10	1
40×25	107	72	60	48	7,350	M10	1
40×30	107	99	60	60	7,240	M10	1
50	102	102	50	50	7,270	M10	1
50×13	102	73	50	52	8,940	M10	1
50×20	102	76	50	52	8,500	M10	1
50×25	102	82	50	58	8,040	M10	1
50×30	102	109	50	70	7,820	M10	1
50×40	102	107	50	60	7,590	M10	1
60	127	127	63	63	9,120	M3	1
60×13	117	81	53	60	10,800	M5	1
60×20	117	84	53	60	10,570	M5	1
60×25	117	84	53	60	10,340	M5	1
60×30	127	109	63	70	10,110	M5	1
60×40	127	117	63	70	10,030	M5	1
60×50	127	112	63	60	9,830	M5	1

S

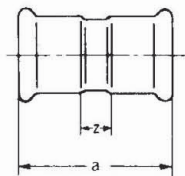


ソケット

呼び径 (Su)	a	z	単価	ケース入数	袋入数
13	53	11	360	S200	25
20	60	12	500	M160	10
25	60	12	570	M120	10
30	100	22	1,600	M40	5
40	116	22	1,960	M30	3
50	126	22	2,220	M30	2
60	154	26	3,200	M10	1

BS

※補修時やり取り用

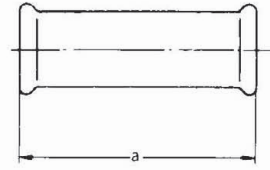


ペアソケット

呼び径 (Su)	a	単価	ケース入数	袋入数
13	116	600	S50	10
20	129	780	S40	10
25	129	890	S20	5
30	100	2,260	S20	5
40	116	2,620	S15	3
50	126	3,110	S15	3
60	154	4,490	M10	1

※パイプ差し込み寸法は、必ず守ってください。(P.10参照)

R

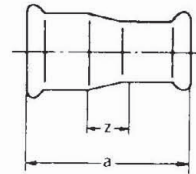


レジューサ

呼び径 (Su)	a	z	単価	ケース入数	袋入数
20×13	60	15	650	S100	10
25×13	75	30	1,210	SS30	10
25×20	64	16	780	S60	10
30×13	105	45	2,420	S30	5
30×20	103	40	2,400	M60	5
30×25	90	27	1,820	M60	5
40×13	123	55	3,010	S20	5
40×20	121	50	2,980	M40	5
40×25	121	50	2,470	M40	5
40×30	122	36	2,300	M20	5
50×13	155	82	3,800	S15	3
50×20	153	77	3,790	S15	3
50×25	131	55	3,130	S15	3
50×30	146	55	2,950	S15	
50×40	133	34	2,630	S10	2
60×13	184	99	5,690	S10	1
60×20	182	94	5,010	S10	1
60×25	183	95	4,690	S10	1
60×30	168	65	4,190	S10	1
60×40	176	65	3,860	S10	1
60×50	157	41	3,480	S5	1

RP

※継手間にパイプを入れずに段落が可能

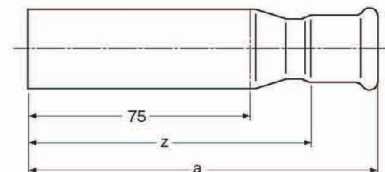

レジューサ付短管

呼び径 (Su)	a	z	単価	ケース入数	袋入数
20×13	106	85	1,590	S50	10

※P.10参照

ケースの大きさは SS:特小(190×170×140mm) S:小(320×200×140mm) M:中(380×320×140mm) L:大(380×320×270mm)