



K3RT

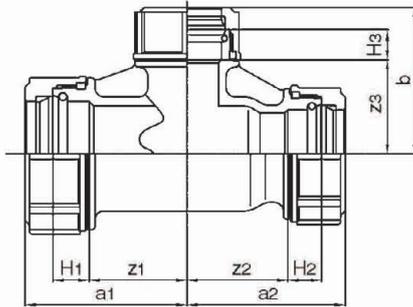

3方異径ティー

| 呼び径 (Su) | a1 | z1 | H1 | a2 | z2 | H2 | b | z3 | H3 | 単価 | ケース入数 | 袋入数 |
|----------|----|----|----|----|----|----|----|----|----|--------|-------|-----|
| 25×20×20 | 47 | 28 | 11 | 46 | 29 | 10 | 46 | 29 | 10 | 4,270 | S10 | 5 |
| 30×25×20 | 54 | 32 | 12 | 52 | 33 | 11 | 48 | 31 | 10 | 7,260 | S10 | 1 |
| 40×30×20 | 61 | 36 | 14 | 60 | 38 | 12 | 53 | 36 | 10 | 9,710 | S10 | 1 |
| 50×40×20 | 66 | 39 | 16 | 66 | 41 | 14 | 57 | 40 | 10 | 10,310 | S5 | 1 |
| 60×50×20 | 76 | 43 | 19 | 73 | 46 | 16 | 64 | 47 | 10 | 12,690 | S3 | 1 |


KRS

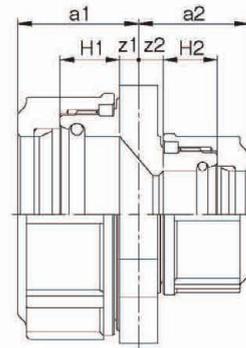

レジュース

| 呼び径 (Su) | a1 | z1 | H1 | a2 | z2 | H2 | 単価 | ケース入数 | 袋入数 |
|----------|----|----|----|----|----|----|-------|-------|-----|
| 20×13 | 21 | 4 | 10 | 21 | 5 | 10 | 1,730 | S50 | 5 |
| 25×13 | 23 | 4 | 11 | 20 | 4 | 10 | 2,300 | S20 | 5 |
| 25×20 | 23 | 4 | 11 | 22 | 5 | 10 | 2,300 | S30 | 5 |
| 30×13 | 26 | 4 | 12 | 23 | 7 | 10 | 3,010 | S20 | 1 |
| 30×20 | 26 | 4 | 12 | 24 | 7 | 10 | 3,010 | S20 | 1 |
| 30×25 | 26 | 4 | 12 | 25 | 6 | 11 | 3,010 | S20 | 1 |
| 40×13 | 29 | 4 | 14 | 22 | 6 | 10 | 4,360 | S20 | 1 |
| 40×20 | 29 | 4 | 14 | 23 | 6 | 10 | 4,360 | S20 | 1 |
| 40×25 | 29 | 4 | 14 | 24 | 5 | 11 | 4,360 | S20 | 1 |
| 40×30 | 29 | 4 | 14 | 26 | 4 | 12 | 4,360 | S20 | 1 |
| 50×20 | 30 | 3 | 16 | 24 | 7 | 10 | 5,610 | S10 | 1 |
| 50×25 | 30 | 3 | 16 | 25 | 6 | 11 | 5,610 | S10 | 1 |
| 50×30 | 30 | 3 | 16 | 27 | 5 | 12 | 5,610 | S10 | 1 |
| 50×40 | 30 | 3 | 16 | 28 | 3 | 14 | 5,610 | S10 | 1 |
| 60×20 | 36 | 3 | 19 | 26 | 9 | 10 | 8,000 | S5 | 1 |
| 60×25 | 36 | 3 | 19 | 27 | 8 | 11 | 8,000 | S5 | 1 |
| 60×30 | 36 | 3 | 19 | 29 | 7 | 12 | 8,000 | S5 | 1 |
| 60×40 | 36 | 3 | 19 | 30 | 5 | 14 | 8,000 | S5 | 1 |
| 60×50 | 36 | 3 | 19 | 30 | 3 | 16 | 8,000 | S5 | 1 |

KS

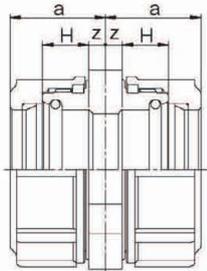


ソケット

| 呼び径 (Su) | a | z | H | 単価 | ケース入数 | 袋入数 |
|----------|----|---|----|-------|-------|-----|
| 13 | 20 | 4 | 10 | 1,610 | S120 | 5 |
| 20 | 22 | 5 | 10 | 1,800 | M100 | 5 |
| 25 | 23 | 4 | 11 | 2,440 | M60 | 5 |
| 30 | 27 | 5 | 12 | 3,260 | S30 | 1 |
| 40 | 28 | 3 | 14 | 4,200 | S20 | 1 |
| 50 | 30 | 3 | 16 | 5,680 | M15 | 1 |
| 60 | 35 | 2 | 19 | 8,300 | M10 | 1 |

KC

※継手本体と袋ナットの
間にはさみ込み使用

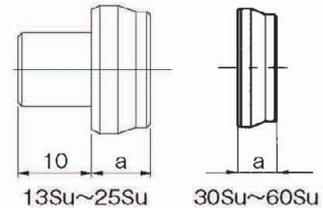

キャップ

| 呼び径 (Su) | a | 単価 | ケース入数 | 袋入数 |
|----------|----|-------|-------|-----|
| 13 | 8 | 670 | S20 | 5 |
| 20 | 10 | 720 | S20 | 5 |
| 25 | 11 | 840 | S20 | 5 |
| 30 | 10 | 960 | S10 | 1 |
| 40 | 12 | 1,270 | S10 | 1 |
| 50 | 12 | 1,610 | S10 | 1 |
| 60 | 15 | 2,390 | S10 | 1 |

※ケースの大きさは SS:特小(190×170×140mm) S:小(320×200×140mm) M:中(380×320×140mm) L:大(380×320×270mm)
 ※図中寸法Hは袋ナットを除いた継手端部からのパイプ差し込み長さです。
 ※パイプ切断寸法は芯々距離からZ寸法を差し引いた長さです。