
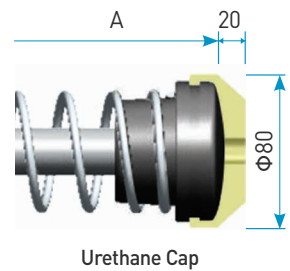



MDA(조정형) 85 Series

Engineering Data


Model	Stroke(mm)	Max.Energy / Cycle (Nm)	Max.Energy / Hour [Nm / h]	Effective Weight (kg)	Recoil Force (N)		Weight (kg)
					Ext.	Comp.	
MDA 85 - 50	50	3,600	416,000	288 ~ 80,000	132	271	6.1
MDA 85 - 100	100	7,200	745,000	576 ~ 160,000	125	327	8.5
MDA 85 - 150	150	10,600	800,000	848 ~ 235,550	127	386	10.8

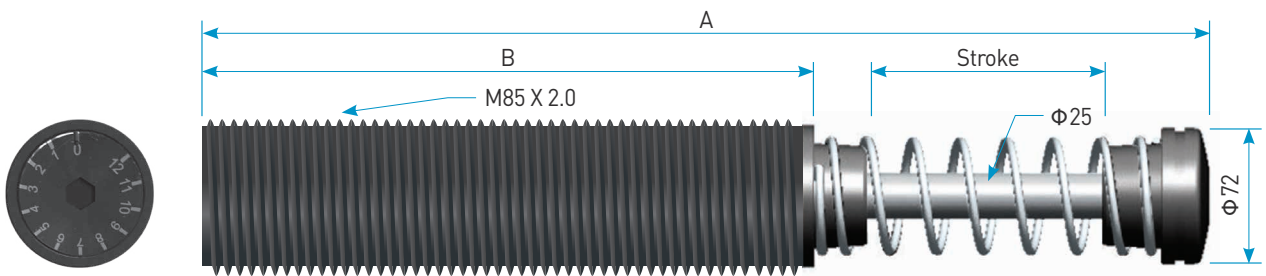

Clamp Mount

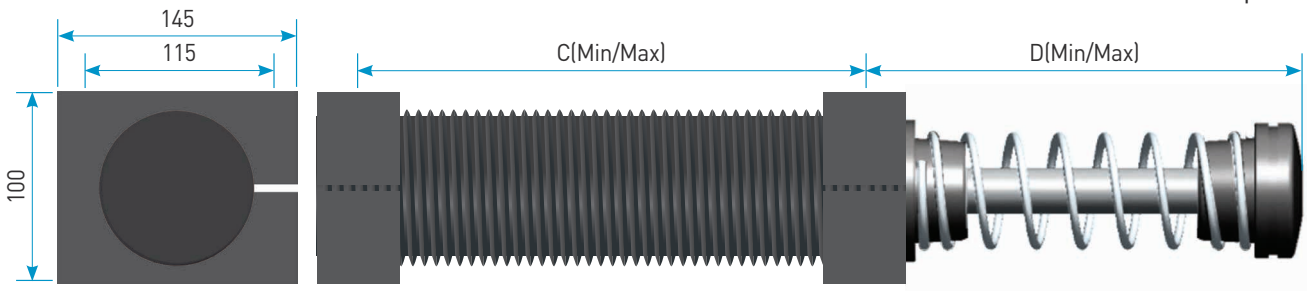

Clevis Mount

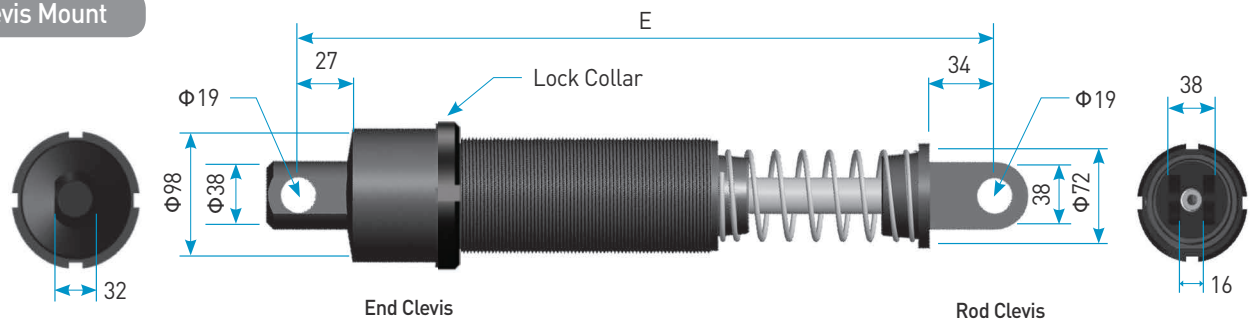

Dimensions

Model	Stroke	A	B	C	D	E
MDA 85-50	50	251	153	25 / 114	120.5 / 162.5	312
MDA 85 - 100	100	384.5	230.5	25 / 187	182.5 / 261	447
MDA 85 - 150	150	513.5	304.5	25 / 262	236.5 / 352.2	-