


Panel Mount Type Speed Control

Uses and Features

- Union speed control valve of panel mount type
- Convenient to attach and detach using hexagon nuts
- Capable of constant speed control

Structural drawing

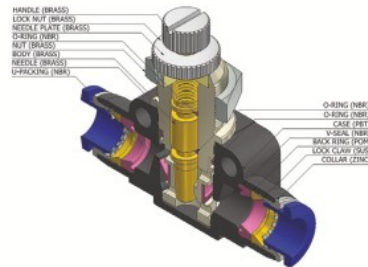

NSFB



MODEL(ϕD)

Tube Metric	Tube Inch
NSFB 04	NSFB $5/32$
NSFB 06	NSFB $3/16$
NSFB 08	NSFB $1/4$
NSFB 10	NSFB $5/16$
NSFB 12	NSFB $3/8$
	NSFB $1/2$

MSFB



MODEL(ϕD)

Tube Metric	
MSFB 04	
MSFB 06	
MSFB 08	
MSFB 10	
MSFB 12	

Product model Number