

Aluminum Profile Industrial Socket Box

Nomenclature

SG - MC - 01 (406502V)

① ② ③

- ① **Product name**
Multi Socket Box
- ② **Number of Socket**
1 / 2 / 3 / 4ea
- ③ **Number of industrial Sockets**
406502V / 406506V



SG-MC-02
(406506V)

SG-MC-02
(406502V)

Model	Size(mm)		
	Width	Height	Length
SG-MC-01 (406502V / 406506V)	90	70	140
SG-MC-02 (406502V / 406506V)			250
SG-MC-03 (406502V / 406506V)			360
SG-MC-04 (406502V / 406506V)			470


Aluminum Profile Socket Box

Nomenclature

SG - MC - 01


① ②

- ① **Product name**
Multi Socket Box
- ② **Number of Sockets**
1 / 2 / 3 / 4 / 5 / 6ea

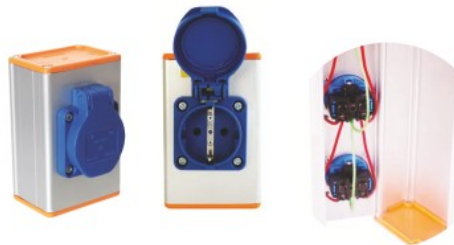

Specifications

Color: Main body - Silver / Side plate - Orange
 Voltage / Current: AC220V~240V / 16A
 Tolerance: ± 1mm
 Operating temperature: -20°C ~ +70°C
 ※ Can be customized

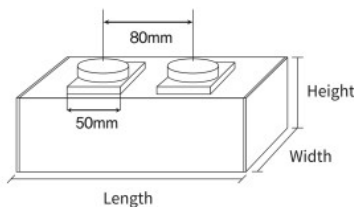

Model	Size(mm)			Model	Size(mm)		
	Width	Height	Length		Width	Height	Length
SG-MC-01	70	50	108	SG-MC-04	70	50	348
SG-MC-02			188	SG-MC-05			428
SG-MC-03			268	SG-MC-06			508

Nomenclature

SG - MC L - 02

① ② ③

- ① **Product name**
Multi Socket Box
- ② **Outlet direction**
Horizontal type (W) / Vertical type (L)
- ③ **Number of Sockets**
2 / 4 / 6 / 8ea


■ Vertical type (L)

■ Horizontal type (W)



Specifications

Color: Main body - Silver / Side plate - Orange
 Operating temperature: -20°C ~ +70°C
 ※ AC 110V 220V types are available / Can be customized

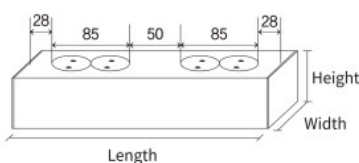

Model	Size(mm)			Model	Size(mm)		
	Width	Height	Length		Width	Height	Length
SG-MCL(W)-02	70	50	141	SG-MCL(W)-06	70	50	411
SG-MCL(W)-04			276	SG-MCL(W)-08			546