


## Test lead LK205-L

Highly flexible with in-line Ø 2 mm MULTILAM plugs on both ends.

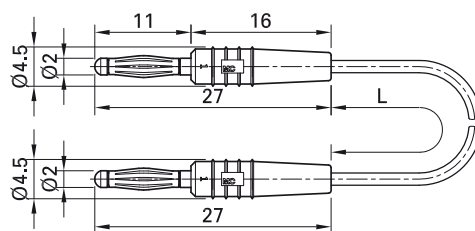

Order No.	Type	Rated voltage/current	Lead		Lead lengths L [cm]	*Standard colors
28.0047-□*	LK205-L	30 VAC / 10 A 60 VDC / 10 A	PVC 0.5 mm <sup>2</sup>	Au	007 (7,5 cm) 015 030 045 060	21 22 23 24 25 26 29



### User information i093

[www.staubli.com/electrical](http://www.staubli.com/electrical)



Optional colors 28

Optional lengths on demand


Further information, page 6

## Test lead SLK205-K...

Highly flexible, with insulation in PVC or silicone with assembled stackable Ø 2 mm

MULTILAM plugs with rigid insulating sleeve on both ends.

SLK205-K...

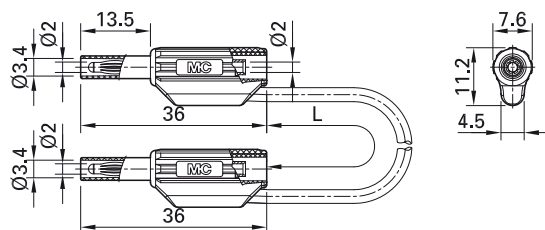

Order No.	Type	Rated voltage/current	Lead		Lead lengths L [cm]	*Standard colors
65.9179-□*	SLK205-K	600 V, CAT II / 10 A	PVC 0.5 mm <sup>2</sup>	Au CE c UL US	030 060 100	21 22 23 24 25
65.9180-□*	SLK205-K/SIL	600 V, CAT II / 10 A	SIL 0.5 mm <sup>2</sup>	Au CE c UL US	045 100	21 22 23



Optional colors 24 25 29

Optional lengths on demand

Further information, page 6