


## Plug SL205-K

Stackable, Ø 2 mm, with spring-loaded MULTILAM, for self-assembly of test leads.

With rigid insulating sleeve. **Solder connection.**

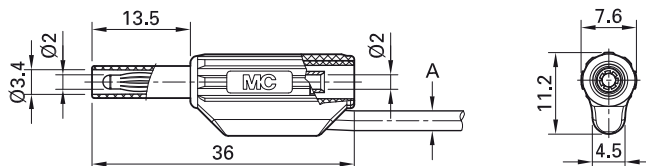

Order No.	Type	Rated voltage/current	Cable (A)		*Standard colors															
65.9182-*	SL205-K	600 V, CAT II / 10 A	<table border="1"> <tr> <td>PVC</td> <td>Ø 2.3 mm</td> <td rowspan="2">0.5 mm<sup>2</sup></td> </tr> <tr> <td>SIL</td> <td>Ø 2.7 mm</td> </tr> </table>	PVC	Ø 2.3 mm	0.5 mm <sup>2</sup>	SIL	Ø 2.7 mm	Au	<table border="1"> <tr> <td>21</td> <td>22</td> <td>23</td> <td>24</td> <td>25</td> </tr> <tr> <td>29</td> <td></td> <td></td> <td></td> <td></td> </tr> </table>	21	22	23	24	25	29				
PVC	Ø 2.3 mm	0.5 mm <sup>2</sup>																		
SIL	Ø 2.7 mm																			
21	22	23	24	25																
29																				



Assembly instructions MAH500


[www.staubli.com/electrical](http://www.staubli.com/electrical)

## Socket SLS205-B

Ø 2 mm rigid for self-assembly of test leads.

Soft insulator.

**Solder connection.**

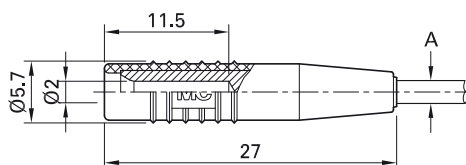

Order No.	Type	Rated voltage/current	Cable (A)		*Standard colors					
22.2621-*	SLS205-B	30 VAC / 10 A 60 VDC / 10 A	<table border="1"> <tr> <td>max. Ø 2.3 mm</td> <td rowspan="2">0.5 mm<sup>2</sup></td> </tr> </table>	max. Ø 2.3 mm	0.5 mm <sup>2</sup>	Au	<table border="1"> <tr> <td>21</td> <td>22</td> <td>23</td> </tr> </table>	21	22	23
max. Ø 2.3 mm	0.5 mm <sup>2</sup>									
21		22	23							

### Component parts

22.2360-*	KT205-S	Insulator
22.1038	LS205-B	Socket



Assembly instructions MA138

[www.staubli.com/electrical](http://www.staubli.com/electrical)