

Panel-mount socket SLB2-...


Insulated, rigid, accepting spring-loaded Ø 2 mm plugs with rigid insulating sleeve. The socket is surface-mounted or assembled flush into pre-drilled panels of plastic, metal, etc.

Connection: Flat connecting tab 2.8 mm x 0.8 mm or round connecting pin Ø 1.9 mm.

SLB2-F2,8



SLB2-R

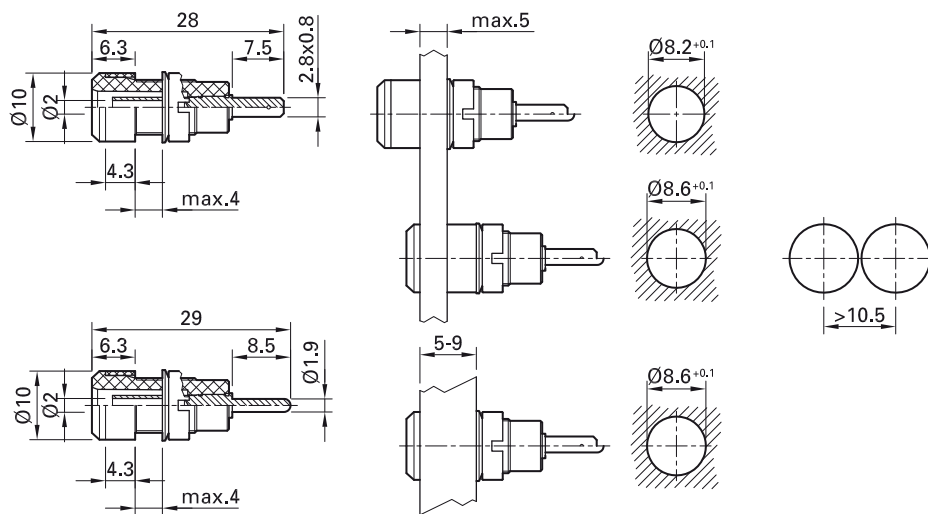

Order No.	Type	Rated voltage/current	Connection		*Standard colors
65.9098-*	SLB2-F2,8	600 V, CAT III / 10 A	Flat connecting tab 2.8 mm x 0.8 mm	Au	21 22 23 24 25 29
65.9194-*	SLB2-R	600 V, CAT III / 10 A	Round connecting pin Ø 1.9 mm	Au c us	21 22 23 24 25 29

Supplied assembly material

		Spacer sleeve for	SLB2-F2,8, SLB2-R
Page 167	MUR/M8x0,5	Round nut for	SLB2-F2,8, SLB2-R
Page 167	SP4	Washer for	SLB2-F2,8, SLB2-R



Flat connecting receptacle FSH2,8x0,8:

page 170

Tube spanners SS4, SS2-S: page 170



Assembly instructions MAH511

www.staubli.com/electrical