



## Test lead LK4-B

Highly flexible, with stackable Ø 4 mm hollow plugs on both ends.

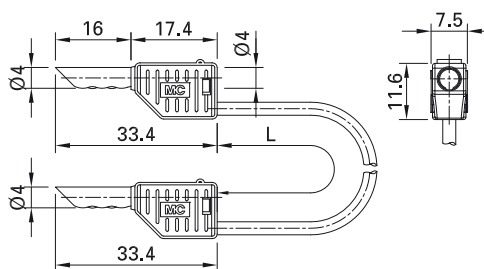

Order No.	Type	Rated voltage/current	Lead		Lead length L [cm]	*Standard colors
28.0055-□*	LK4-B	30 VAC / 19 A 60 VDC / 19 A	PVC 1.0 mm <sup>2</sup>	Au	050	21 22 23 24
28.0056-□*	LK4-B/SIL	30 VAC / 19 A 60 VDC / 19 A	SIL 1.0 mm <sup>2</sup>	Au	050	21 22

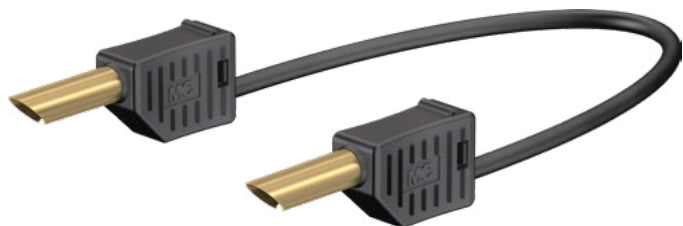

Optional colors 23 24 25 26 29

Optional lengths on demand

Further information, page 6



**User information i096**

[www.staubli.com/electrical](http://www.staubli.com/electrical)