
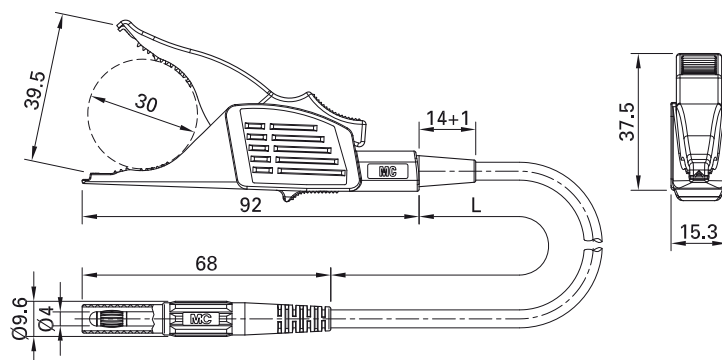


## Test clip lead XDLS-418

Highly flexible. One end with dolphin clip with all-round insulation, toothed jaws for wide grip and surface for fine wire. The other

end with Ø 4 mm MULTILAM plug with rigid insulating sleeve.

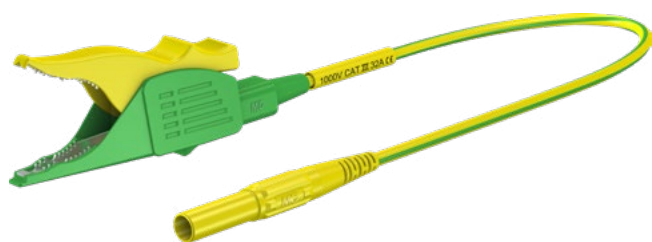

Order No.	Type	Rated voltage/current	Lead		Lead length [cm]	*Standard colors
66.9531-150*	XDLS-418	1000 V, CAT III / 32 A	PVC 2.5 mm <sup>2</sup>	Ni CE	150	20 21 22





Optional colors 23 24 25 26 27 28 29

Further information, page 6

## Test clip GRIP-CI

With steel jaws especially for connections to ground rails and thick cables. For increased safety when making connections, the jaws

are insulated on the outside. Ø 4 mm rigid socket in handle accepting spring-loaded Ø 4 mm plugs with rigid insulating sleeve.

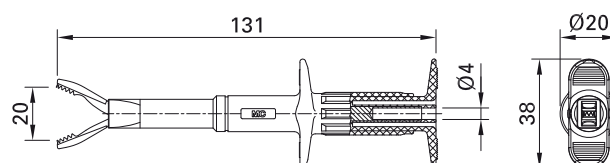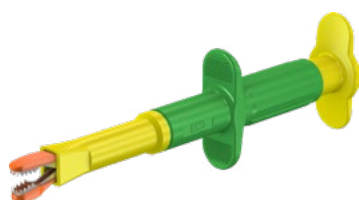

Order No.	Type	Rated voltage/current		*Standard colors
66.9121-*	GRIP-CI	1000 V, CAT III / 16 A	Ni CE c UL US	20 21 22 23 24 25 26



Optional colors 29

Further information, page 6