


# フリーアングル


Unique Design 360° rotation fitting FREE-ANGLE FITTING

## フリーアングル ST タイプ FREE ANGLE ST TYPE

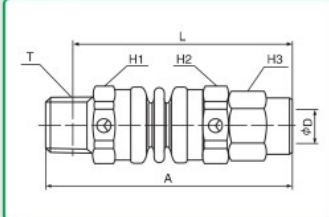


型式 Model	A	ホース内外径 Hose Size I.D. x O.D. x D	二面幅 Spanner Flats			L	ねじサイズ Thread T	有効断面積 Effective Section Area (mm <sup>2</sup> )	重量 Weight (g)
			H1	H2	H3				
3FA2M-6.5H	63.4	6.5×10	19.0	19.0	16.0	57.4	R1/4	20	68
3FA3M-6.5H	64.4	6.5×10	19.0	19.0	16.0	58.0	R3/8	20	74
3FA2M-8H	65.8	8×12	19.0	19.0	19.0	59.8	R1/4	25	81
3FA3M-8H	66.8	8×12	19.0	19.0	19.0	60.4	R3/8	25	87

## フリーアングル ST タイプ FREE ANGLE ST TYPE

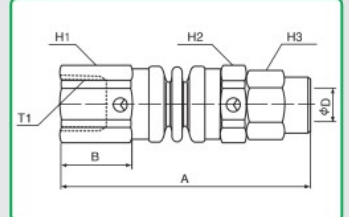


型式 Model	A	B	ホース内外径 Hose Size I.D. x O.D. x D	二面幅 Spanner Flats			ねじサイズ Thread T	有効断面積 Effective Section Area (mm <sup>2</sup> )	重量 Weight (g)
				H1	H2	H3			
3FAG2F-6.5H	63.2	15.5	6.5×10	17.0	19.0	16.0	G1/4	20	77
3FA3F-6.5H	65.9	19.0	6.5×10	21.0	19.0	16.0	Rc3/8	20	87
3FAG2F-8H	65.6	15.5	8×12	19.0	19.0	19.0	G1/4	25	91
3FA3F-8H	68.3	19.5	8×12	21.0	19.0	19.0	Rc3/8	25	101

## フリーアングル M タイプ FREE ANGLE M TYPE

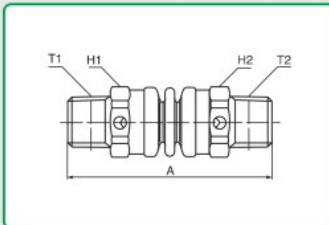


型式 Model	A	二面幅 Spanner Flats		ねじサイズ Thread		有効断面積 Effective Section Area (mm <sup>2</sup> )	重量 Weight (g)
		H1	H2	T1	T2		
3FA2M-2M	55.9	19.0	19.0	R1/4	R1/4	25	52
3FA3M-3M	57.8	19.0	19.0	R3/8	R3/8	25	62

## フリーアングル FM タイプ FREE ANGLE FM TYPE

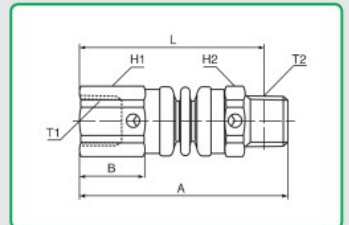

型式 Model	A	B	二面幅 Spanner Flats		L	ねじサイズ Thread		有効断面積 Effective Section Area (mm <sup>2</sup> )	重量 Weight (g)
			H1	H2		T1	T2		
3FAG2F-2M	55.7	15.5	19.0	19.0	49.7	G1/4	R1/4	25	61
3FA3F-3M	59.3	19.5	21.0	19.0	52.9	Rc3/8	R3/8	25	76


## フリーアングル P タイプ FREE ANGLE P TYPE

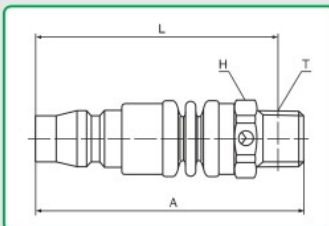

型式 Model	A	二面幅 Spanner Flats H	L	ねじサイズ Thread T	有効断面積 Effective Section Area (mm <sup>2</sup> )	重量 Weight (g)
3FAP-3M	68.0	19.0	61.6	R3/8	25	62
3FAP-G2F	66.8	19.0	-	G1/4	25	66
3FAP-02MR	82.0	19.0	76.0	R1/4	25	86

3FAP-02MRは流量調整ツマミ付きフリーアングル継手です。  
3FAP-02MR has Air Flow Regulator.

## フリーアングル F タイプ FREE ANGLE F TYPE

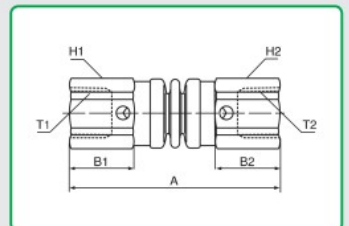

型式 Model	A	B1	B2	二面幅 Spanner Flats		ねじサイズ Thread		有効断面積 Effective Section Area (mm <sup>2</sup> )	重量 Weight (g)
				H1	H2	T1	T2		
3FAG2F-G2F	55.5	15.5	17.0	19.0	19.0	G1/4	G1/4	25	69
3FA3F-3F	60.8	19.5	19.0	21.0	21.0	Rc3/8	Rc3/8	25	88