


ダイスライドスラストワッシャー-TA寸法表 (プッシュ内径φ10.2~φ120.5)

部品番号の表示方法

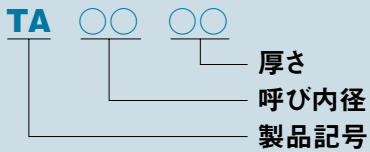

TA 1003

Parts No.でご指示ください

寸法(mm)		肉 厚 ${}^0_{-0.1}$					
内 径	外 径	3	5	7	8	10	
10.2	30	TA1003					
12.2	40	TA1203					
12.2	40	TA1203N					
13.2	40	TA1303					
14.2	40	TA1403					
15.2	50	TA1503					
16.2	50	TA1603					
16.2	50	TA1603N					
18.2	50	TA1803					
20.2	50		TA2005				
25.2	55		TA2505				
30.2	60		TA3005				
35.2	70		TA3505				
40.2	80			TA4007			
45.2	90			TA4507			
50.3	100				TA5008		
55.3	110				TA5508		
60.3	120				TA6008		
65.3	125				TA6508		
70.3	130					TA7010	
75.3	140					TA7510	
80.3	150					TA8010	
90.5	170					TA9010	
100.5	190					TA10010	
120.5	200					TA12010	

※ベース金属は高力黄銅です。