


# 銅線用裸圧着端子 **フック形端子** 〈H形〉

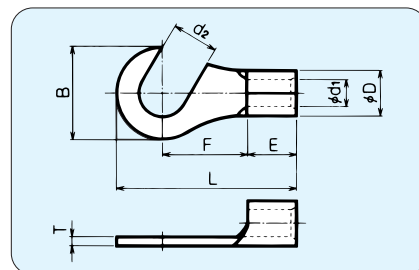


RoHS 指令対応品

規格	呼び	各部の寸法								適合電線範囲			適合工具	一箱入数		
		d <sub>2</sub>	B	L	F	E	φD	φd <sub>1</sub>	T	単線mm	撚線mm <sup>2</sup>	AWG				
UL	SP	H1.25-3	3.2	5.5	13.8	6.6	4.5	3.4	1.7	0.8	0.57 ∩ 1.44	0.25 ∩ 1.65	22-16	DS031 ≡ニ12 5N18 DH-1B AC-5N-D	1,000 (100×10)	
UL	SP	H1.25-4	4.3	8.0	15.8	7.3										
UL	SP	H1.25-5	5.3													
UL	SP	H1.25-6	6.4	11.5	20.2	10.0										
UL	SP	H2-3	3.2	8.0	16.8	8.3	4.5	4.2	2.3	0.8	1.14 ∩ 1.82	1.04 ∩ 2.63	16-14	≡ニ12 5N18,214A DH-1B AC-5N-D REC-14A	1,000 (100×10)	
UL	SP	H2-4	4.3	8.5												
UL	SP	H2-5	5.3	9.5												17.7
UL	SP	H2-6	6.4	12.0												22.0
UL	SP	H2-8	8.4													
UL	SP	H3.5-4	4.3	8.5	17.8	8.3	5.3	5.0	3.0	1.0	1.82~2.4	2.63~4.6	12	5N18,214A DH-1B AC-5N-D REC-14A	* 1,000	
UL	SP	H5.5-4	4.3	9.5	21.3	10.2	6.3	5.6	3.4	1.0	1.82 ∩ 2.89	2.63 ∩ 6.64	12-10			
UL	SP	H5.5-5	5.3													
UL	SP	H5.5-6	6.4	12.0	25.8	13.5										
UL	SP	H5.5-8	8.4	15.0	27.3											

1. 各呼びの印は、UL登録品、CSA登録品です。
2. CSA登録品としてご使用の際は、注文時にご指示ください。カートンがCSA品用となります。
3. \*印は100個箱入り数量です。

# 銅線用裸圧着端子 **横開形端子** 〈HY形〉

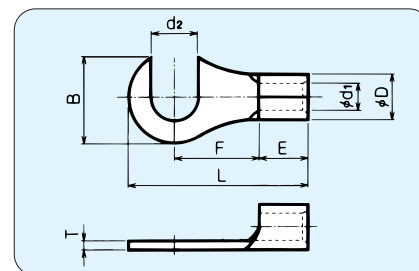

RoHS 指令対応品

規格	呼び	各部の寸法								適合電線範囲			適合工具	一箱入数	
		d <sub>2</sub>	B	L	F	E	φD	φd <sub>1</sub>	T	単線mm	撚線mm <sup>2</sup>	AWG			
UL		HY1.25-3	3.2	5.0	12.2	5.0	4.5	3.4	1.7	0.8	0.57 ∩ 1.44	0.25 ∩ 1.65	22-16	DS031 ≡ニ12 5N18 DH-1B AC-5N-D	1,000 (100×10)
UL	SP	HY1.25-4	4.3	7.2	15.8	7.3									
UL	SP	HY1.25-5	5.3	7.0											
UL	SP	HY2-4	4.3	7.8	17.0	8.3	4.5	4.2	2.3	0.8	1.14 ∩ 1.82	1.04 ∩ 2.63	16-14	≡ニ12,5N18 214A,DH-1B AC-5N-D,REC-14A	1,000 (100×10)
UL	SP	HY2-5	5.3	8.7	17.5										
UL	SP	HY8-6	6.4	11.0	23.8	9.5	8.3	7.1	4.5	1.2	2.89~3.65	6.64~10.52	8	5N18,214A,REC-14A	400 (100×4)

1. 各呼びの印は、UL登録品、CSA登録品です。
2. CSA登録品としてご使用の際は、注文時にご指示ください。カートンがCSA品用となります。
3. 上記寸法表にかぎらず特注品もご相談ください。