



## Front & back chamfering


Single insert type

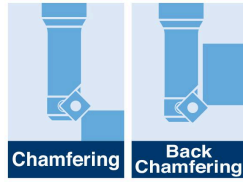

World's smallest  
Hexagon insert

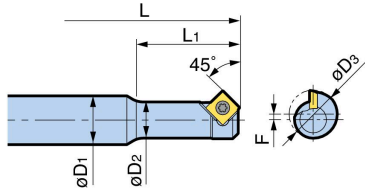

Detailed dimension

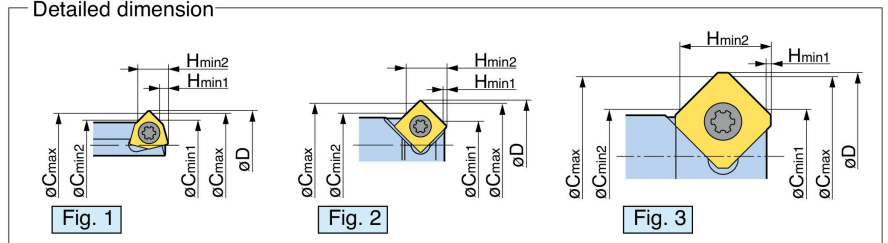

Model	Fig.	øD	øD1	øD2	øD3	L	L1	øCmin1	øCmin2	øCmax	Hmin1	Hmin2	Offset F	Insert Model
ST10-C0608-45B-16	1	8.8	10	5.7	5.7	78	16	6	6	8	1.0	3.8	1.55	CM04...
ST10-C0409-45B-20	2	9.8	10	5.4	7.7	86	20	4	6	9	0.5	5.4	1.1	CM05...
ST10-C0611-45B-20	2	12.0	10	7.4	9.8	81	20	6	8	11	0.4	5.5	1.1	CM05...
-35						96	35							
ST16-C1222-45B-40	3	22.6	16	11.0	16.9	117	40	12	12	22	0.3	12.4	2.9	CM10...

1. Wrench and screw are included. Inserts are ordered separately (10/pkg).
2. 10 screws and 1 wrench are included in Insert Clamping Screw Set.

Refer to table A on page I 29 for cutting conditions.

For Insert : I 29