
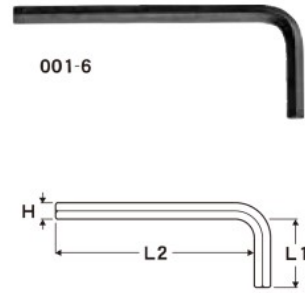


001-*

INDIVIDUAL (mm. size / inch size)

SURFACE TREATMENT : Black parkerized finish / PACKAGE : Bulk pack

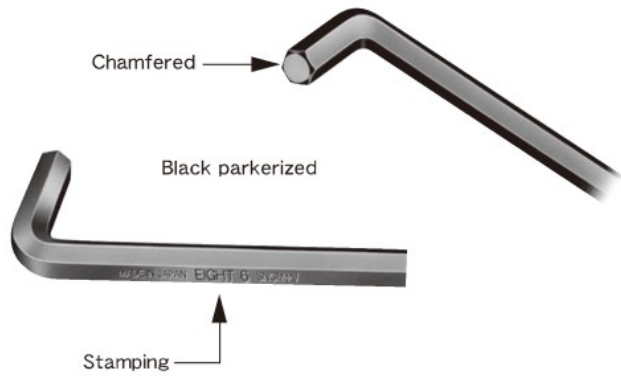

METRIC SIZE

Item No.	H	L1	L2	Inner	D×W×H	g
001-0.71mm	0.71 (0.028")	8	34	100	100×80×55	50
001-0.89mm	0.89 (0.035")	10	34	100	100×80×55	58
001-1.27mm	1.27 (0.05")	14	46	100	100×80×55	96
001-1.4mm	1.4	11	50	100	100×80×55	110
001-1.5mm	1.5	12	52	100	100×80×55	128
001-2mm	2	12	58	100	100×80×55	219
001-2.5mm	2.5	15	60	100	100×80×55	345
001-3mm	3	20	65	100	100×80×55	542
001-3.5mm	3.5	22	68	100	100×80×55	774
001-4mm	4	25	72	100	115×85×52	1,083
001-4.5mm	4.5	27	76	100	115×85×52	1,449
001-5mm	5	28	80	100	141×95×58	1,872
001-5.5mm	5.5	30	85	100	141×95×58	2,426
001-6mm	6	32	90	100	148×123×66	3,029
001-7mm	7	34	95	50	141×95×58	2,209
001-8mm	8	36	100	50	148×123×66	3,039
001-9mm	9	38	106	50	156×127×65	4,059
001-10mm	10	40	112	30	148×123×66	3,171
001-11mm	11 (7/16")	42	118	25	156×127×65	3,465
001-12mm	12	45	125	20	156×127×65	3,467
001-13mm	13	57	132	10	115×85×52	2,172
001-14mm	14	55	140	10	115×85×52	2,687
001-15mm	15	63	150	10	193×129×54	3,276
001-16mm	16 (5/8")	57	153	10	193×129×54	3,724
001-17mm	17	60	160	10	203×135×54	4,455
001-18mm	18	70.5	170.5	6	203×115×68	3,221
001-19mm	19 (3/4")	70	175	6	203×115×68	3,735
001-20mm	20	72	185	6	214×120×69	4,376
001-21mm	21	75	198	6	238×128×79	5,150
001-22mm	22	80	200	6	238×128×79	5,800
001-23mm	23	85	210	-	-	-
001-24mm	24	90	225	-	-	-
001-26mm	26	95	245	-	-	-
001-27mm	27	100	250	-	-	-
001-30mm	30	120	290	-	-	-
001-32mm	32	125	315	-	-	-
001-36mm	36	130	320	-	-	-
001-41mm	41	140	390	-	-	-
001-46mm	46	155	410	-	-	-
001-50mm	50	170	430	-	-	-

INCH SIZE

Item No.	H	L1	L2	Inner	D×W×H	g
001-0.028"	0.028" (0.71mm)	8	34	100	100×80×55	50
001-0.035"	0.035" (0.89mm)	10	34	100	100×80×55	58
001-0.05"	0.05" (1.27mm)	14	46	100	100×80×55	96
001-1/16"	1/16"	13	46	100	100×80×55	130
001-5/64"	5/64"	14	50	100	100×80×55	200
001-3/32"	3/32"	17	56	100	100×80×55	303
001-7/64"	7/64"	18	58	100	100×80×55	424
001-1/8"	1/8"	20	59	100	100×80×55	568
001-9/64"	9/64"	22	65	100	100×80×55	784
001-5/32"	5/32"	24	68	100	115×85×52	1,007
001-3/16"	3/16"	25	75	100	141×95×58	1,583
001-7/32"	7/32"	27	81	100	141×95×58	2,291
001-1/4"	1/4"	30	88	100	148×123×66	3,273
001-9/32"	9/32"	34	95	50	141×95×58	2,296
001-5/16"	5/16"	34	98	50	148×123×66	2,871
001-3/8"	3/8"	37	110	30	148×123×66	2,792
001-7/16"	7/16" (11mm)	42	118	25	156×127×65	3,465
001-1/2"	1/2"	45	125	20	156×127×65	3,859
001-9/16"	9/16"	55	138	10	184×123×48	2,788
001-5/8"	5/8" (16mm)	57	153	10	193×129×54	3,724
001-3/4"	3/4" (19mm)	70	175	6	203×115×68	3,735
001-7/8"	7/8"	80	200	6	238×128×79	5,810
001-1"	1"	95	235	-	-	-

EXCELLENT
STANDARD
TORX®
TORX®
L
TYPE
KNIFE
TYPE
SCREW DRIVER
TYPE
T-HANDLE
TYPE
SOCKET BIT
TYPE
BIT
TYPE