


베이스						
Elesa 표준		장착 홀		풀 아웃(Pull out) #	회전 내성 #	q
코드	설명	s	d	[N]	[Nm]	g
440101	MSX.56-B-8-10	8	10	900	4	32
440102	MSX.56-B-10-12	10	12	1000	4.5	31
440103	MSX.56-B-12-14	12	14	1100	5	28

#동근 튜브와 함께 테스트함.

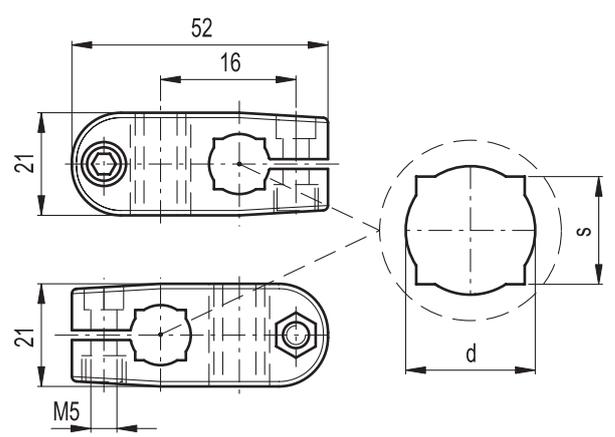

T자형 클램프						
Elesa 표준		장착 홀		풀 아웃(Pull out) #	회전 내성 #	q
코드	설명	s	d	[N]	[Nm]	g
440121	MSX.56-C-8-10	8	10	900	4.5	24
440122	MSX.56-C-10-12	10	12	1000	5	23
440123	MSX.56-C-12-14	12	14	1100	5.5	20

#동근 튜브와 함께 테스트함.