



TV-25 · 26 · 27

 YANKEE VISE

- With special clasp ideal for thin plate, round bar and square lumber.
- The reverse of the clasp to be used as a flat clasp.

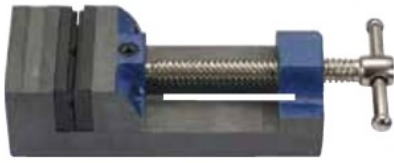

TV-26

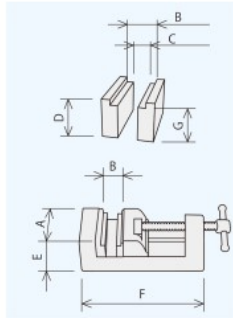

| Item No. | Size(mm) |    |    |    |    |       |      | Clamp Force Max.(KN) |
|----------|----------|----|----|----|----|-------|------|----------------------|
|          | A        | B  | C  | D  | E  | F     | G    |                      |
| TV-25    | 50       | 61 | 55 | 32 | 53 | 145   | 27.5 | 3                    |
| TV-26    | 65       | 76 | 70 | 32 | 53 | 170   | 27.5 | 4                    |
| TV-27    | 75       | 84 | 78 | 38 | 62 | 181.5 | 33   | 5                    |

TF-06 · 07 · 10

 
 

FILE



TF-07



TF-10

| Item No. | Shape   | Length(mm) | Grip   |
|----------|---|------------|--------|
| TF-06    |  | 200        | Rubber |
| TF-07    |  |            |        |
| TF-10    |  |            |        |

TN-01W~05W

 JEWELLER'S SAW

- Light weight, durable and well-balanced frame design.
- Wooden handle is shaped for sure and comfortable grip.
- Saw frame is designed to be adjustable in length and capable of using even broken pieces of saw blades. (TN-04W/05W)

- Blade contained TN-17 (standard) TN-13 & 15 (spare)
- The ideal saw blades made of SKS special steel alloy with the technological know-how.
- Entirely heat treated, best quality saw blades available.

| Item No. | Frame Size (WxD) | Weight(g) |
|----------|------------------|-----------|
| TN-01W   | 125 x 75 mm      | 135       |
| TN-02W   | 125 x 125 mm     | 160       |
| TN-03W   | 110 x 275 mm     | 215       |
| TN-04W   | ~145 x 75 mm     | 170       |
| TN-05W   | ~145 x 125 mm    | 190       |

TN-05W  
(※Frame length adjustable(TN-04W/05W))

TN-11~18

 SAW BLADES

- Applications: Aluminum, Brass, Sheetmetal, etc.
- Overall length: 130mm

TN-17

| Item No. | Nominal Size | Blade Thick (mm) | Notches/25mm |
|----------|--------------|------------------|--------------|
| TN-11    | #3/0         | 0.24             | 61           |
| TN-12    | #2/0         | 0.26             | 56           |
| TN-13    | #0           | 0.28             | 53.5         |
| TN-14    | #1           | 0.30             | 51           |
| TN-15    | #2           | 0.34             | 43           |
| TN-16    | #3           | 0.36             | 40.5         |
| TN-17    | #4           | 0.38             | 38           |
| TN-18    | #5           | 0.40             | 35.5         |

TM-04 · 05

 STEEL RULE

TM-04



| Item No. | Scale |
|----------|-------|
| TM-04    | 15 cm |
| TM-05    | 30 cm |

TZ-02 · 04

 HANDY SAW


TZ-02 Adjustable blade



| Item No. | Blade Size     | Shape        | Length |
|----------|----------------|--------------|--------|
| TZ-02    | 250mm24notches | Plastic Grip | 260mm  |

- Replacement blade TZ-04 (12pcs/dozen)

TZ-05 · 13

 SCRIBER

- Metal work to mark a point or draw a line on the workpiece.

SCRIBER  
TZ-05  
● 210mm



CARBIDE SCRIBING PEN  
TZ-13  
● 138mm  
● Retractable tip for safe storage and carrying



TZ-07 · 14

PUNCH

PUNCH  
TZ-07  
● 100mm



AUTO CENTER PUNCH  
TZ-14  
● 138mm  
● Carbide tip  
● Press down the tip to punch a hole automatically.



SCREW REMOVAL

SCISSORS

NIPPERS

PLIERS

CRIMPING STRIPPING

TWEEZERS

SCREW DRIVERS

SPECIAL DRIVERS

WRENCHES

CUTTING PROCESSING

SETS CASES

SOLDERING EQUIPMENT

ESD CHEMICALS