




Applications

- CeFiX® registered system by EVAC
- Seals reusable up to 10 times
- Use for cryo applications down to -271 degC
- Use for high temperature applications
- Al. up to 200 degC, copper up to 300 degC, nickel up to 450 degC
- Radiation tolerant
- Use for overpressure applications (nickel up to 300 bar)

38

EVAC KF - CeFiX® seals

NW	B
16	21.4
25	32.9
40	48.3
50	61.8
63	82.55

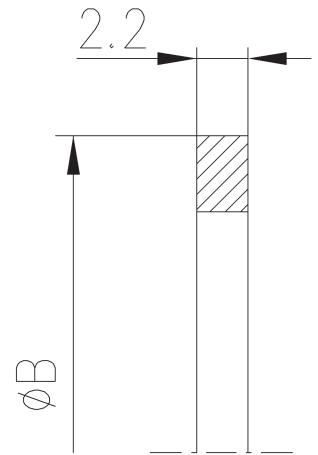

Type NW	Aluminium	OFS Copper	OFS Copper silver-plated	Nickel
16	34.016001.663.101	34.016070.663.401	34.016073.663.901	34.016068.663.601
25	34.025001.663.102	34.025070.663.402	34.025073.663.902	34.025068.663.602
40	34.040001.663.104	34.040070.663.404	34.040073.663.904	34.040068.663.604
50	34.050001.663.105	34.050070.663.405	34.050073.663.905	
63	34.063001.663.106	34.063070.663.406	34.063073.663.906	