



(単位：mm)

エルボレデューサーユニオン(突合わせ溶接タイプ)

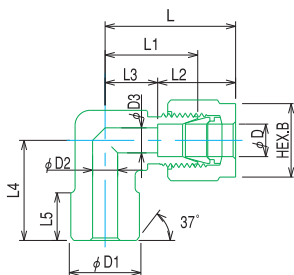


呼び径D	D1	D2	D3	B	L	L1	L2	L3	L4	L5	品番
6.35	10.3	4.8	5	14	25.5	18.5	15	10.5	20	11	F900-LR-6.35×10.3M
6.35	13.7	7.1	5	14	25.5	18.5	15	10.5	22	11.5	F900-LR-6.35×13.7M
9.52	13.7	7.1	7.5	17	30	22	17.5	12.5	25	13	F900-LR-9.52×13.7M
12.7	21.35	13.2	10	22	36	25	24	12	32	17	F900-LR-12.7×21.35M

ティーユニオン

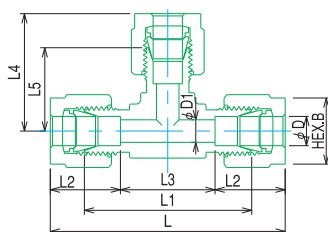


呼び径D	D1	B	L	L1	L2	L3	L4	L5	品番
3.2	2.7	10	47	34	13	21	23.5	17	F900-T-3.2
6.35	5	14	51	37	15	21	25.5	18.5	F900-T-6.35
9.52	7.5	17	60	44	17.5	25	30	22	F900-T-9.52
12.7	10	22	72	50	24	24	36	25	F900-T-12.7
19.05	16	29	82	60	25.2	31.6	41	30	F900-T-19.05
25.4	22.4	38	98	73.6	31.2	35.6	49	36.8	F900-T-25.4

異径ティーユニオン

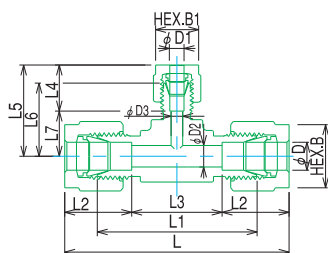

呼び径D	呼び径D1	D2	D3	B	B1	L	L1	L2	L3	L4	L5	L6	L7	品番
9.52	6.35	7.5	5	17	14	60	44	17.5	25	15	29	22	14	F900-T-9.52×9.52×6.35
12.7	6.35	10	5	22	14	72	50	24	24	15	32	25	17	F900-T-12.7×12.7×6.35
12.7	9.52	10	7.5	22	17	72	50	24	24	17.5	33	25	15.5	F900-T-12.7×12.7×9.52
19.05	6.35	16	5	29	14	82	60	25.2	31.6	15	37	30	22	F900-T-19.05×19.05×6.35
19.05	9.52	16	7.5	29	17	82	60	25.2	31.6	17.5	38	30	20.5	F900-T-19.05×19.05×9.52
19.05	12.7	16	10	29	22	82	60	25.2	31.6	24	41	30	17	F900-T-19.05×19.05×12.7
25.4	19.05	22.4	16	38	29	97.9	73.6	31.2	35.5	25.2	47.8	36.8	22.6	F900-T-25.4×25.4×19.05

クロスユニオン

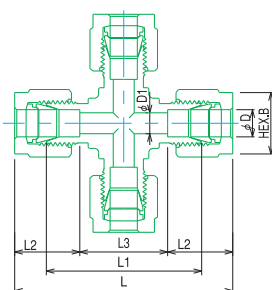

呼び径D	D1	B	L	L1	L2	L3	品番
3.2	2.7	10	47	34	13	21	F900-X-3.2
6.35	5	14	51	37	15	21	F900-X-6.35
9.52	7.5	17	60	44	17.5	25	F900-X-9.52
12.7	10	22	72	50	24	24	F900-X-12.7