
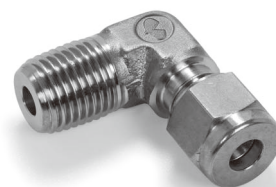


## エルボーフユニオン(NPT)

L

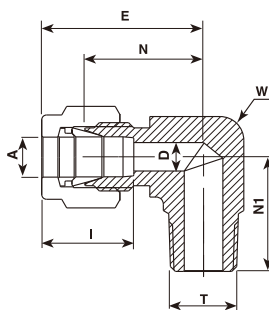

### チューブ(ミリサイズ)とNPTおねじ

品番	A	T	D	W		N	E	N1	I
	呼び径 mm		mm	in	mm	mm	mm	mm	mm
VUWL-3AN	3	1/8NPT	2.4	7/16	11.1	17	23.6	17.8	12.9
VUWL-3BN	3	1/4NPT	2.4	1/2	12.7	18	24.6	23.4	12.9
VUWL-4AN	4	1/8NPT	2.4	1/2	12.7	18.8	25.4	18.8	13.7
VUWL-4BN	4	1/4NPT	2.4	1/2	12.7	18.8	25.4	23.4	13.7
VUWL-6AN	6	1/8NPT	4.8	1/2	12.7	19.6	27	18.8	15.3
VUWL-6BN	6	1/4NPT	4.8	1/2	12.7	19.6	27	23.4	15.3
VUWL-6CN	6	3/8NPT	4.8	11/16	17.5	22.4	29.8	26.2	15.3
VUWL-6DN	6	1/2NPT	4.8	13/16	20.6	24.4	31.8	33	15.3
VUWL-8AN	8	1/8NPT	4.8	9/16	14.3	21.3	28.8	19.8	16.2
VUWL-8BN	8	1/4NPT	6.4	9/16	14.3	21.3	28.8	24.4	16.2
VUWL-8CN	8	3/8NPT	6.4	11/16	17.5	23.1	30.6	26.2	16.2
VUWL-8DN	8	1/2NPT	6.4	13/16	20.6	25.1	32.6	33	16.2
VUWL-10AN	10	1/8NPT	4.8	11/16	17.5	23.9	31.5	21.6	17.2
VUWL-10BN	10	1/4NPT	7.1	11/16	17.5	23.9	31.5	26.2	17.2
VUWL-10CN	10	3/8NPT	7.9	11/16	17.5	23.9	31.5	26.2	17.2
VUWL-10DN	10	1/2NPT	7.9	13/16	20.6	25.9	33.5	33	17.2
VUWL-12AN	12	1/8NPT	4.8	13/16	20.6	25.9	36	23.6	22.8
VUWL-12BN	12	1/4NPT	7.1	13/16	20.6	25.9	36	28.2	22.8
VUWL-12CN	12	3/8NPT	9.5	13/16	20.6	25.9	36	28.2	22.8
VUWL-12DN	12	1/2NPT	9.5	13/16	20.6	25.9	36	33	22.8
VUWL-12EN	12	3/4NPT	9.5	1 1/8	28.6	29.7	39.8	36.8	22.8
VUWL-15DN	15	1/2NPT	11.9	15/16	23.8	27.9	38	35.1	24.4
VUWL-16CN	16	3/8NPT	9.5	15/16	23.8	27.9	38	30.2	24.4
VUWL-16DN	16	1/2NPT	11.9	15/16	23.8	27.9	38	35.1	24.4
VUWL-16EN	16	3/4NPT	12.7	1 1/8	28.6	29.7	39.8	36.8	24.4
VUWL-18DN	18	1/2NPT	11.9	1 1/8	28.6	29.7	39.8	36.8	24.4
VUWL-18EN	18	3/4NPT	15.1	1 1/8	28.6	29.7	39.8	36.8	24.4
VUWL-20DN	20	1/2NPT	11.9	1 3/8	34.9	34.5	44.6	41.7	26
VUWL-20EN	20	3/4NPT	15.9	1 3/8	34.9	34.5	44.6	41.7	26
VUWL-22EN	22	3/4NPT	15.9	1 3/8	34.9	34.5	44.6	41.7	26
VUWL-22FN	22	1NPT	18.3	1 3/8	34.9	34.5	44.6	46.5	26
VUWL-25EN	25	3/4NPT	15.9	1 3/8	34.9	36.8	49.1	41.7	31.3
VUWL-25FN	25	1NPT	21.8	1 3/8	34.9	36.8	49.1	46.5	31.3

インチは次ページ参照

※"D" - 寸法は最小穴径です。 ※技術の進歩のために使用材料、寸法など予告なく多少変更することがありますのであらかじめご了承下さい。