


枠式ターンバックル・ジョウ (戻り止めナット付)



SUS 304

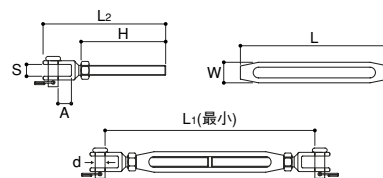


品番	ネジ径 (W)	L (mm)	L1 (mm)	L2 (mm)	d (mm)	H (mm)	S (mm)	A (mm)	W (mm)	Weight (g)	使用荷重 (kgf)	価格
TB- 5J	W-3/16	70	110	66	6	40	9.5	10	14	70	100	¥ 1,730
TB- 6J	W-1/ 4	90	135	80	8	50	10.0	10	19	140	120	¥ 2,160
TB- 8J	W-5/16	120	179	100	10	62	12.0	13	21	260	250	¥ 4,070
TB- 9J	W-3/ 8	150	223	123	12	77	15.0	18	26	450	300	¥ 5,310
TB-12J	W-1/ 2	200	280	145	12	100	15.0	18	34	735	500	¥ 8,580
TB-16J	W-5/ 8	250	353	190	14	125	22.0	25	40	1,380	800	¥16,800

ターンバックル・ジョウ (戻り止めナット付)



SUS 316

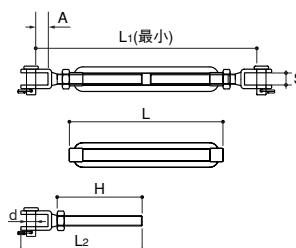

品番	ネジ径 (mm)	L (mm)	L1 (mm)	L2 (mm)	d (mm)	H (mm)	S (mm)	A (mm)	Weight (g)	使用荷重 (kg)	価格
TB- 5J-316	M 5	70	108	62.0	5.0	40	6.8	10	55	100	¥ 2,340
TB- 6J-316	M 6	90	132	75.0	6.0	51	7.2	10	95	120	¥ 2,800
TB- 8J-316	M 8	120	172	98.5	8.0	69	11.3	11	190	250	¥ 5,760
TB-10J-316	M10	150	210	120.0	9.0	85	12.0	13	335	300	¥ 7,000
TB-12J-316	M12	200	283	160.0	12.0	110	14.0	21	635	500	¥10,300
TB-16J-316	M16	250	314	185.0	15.5	112	17.3	26	1,100	800	¥20,300
TB-20J-316	M20	300	420	225.0	19.5	147	20.5	29	2,150	1,000	¥31,200