


## F / FR / FS series

조절자

**kg** 1,000 ~ 4,000 kg

✓ RoHS

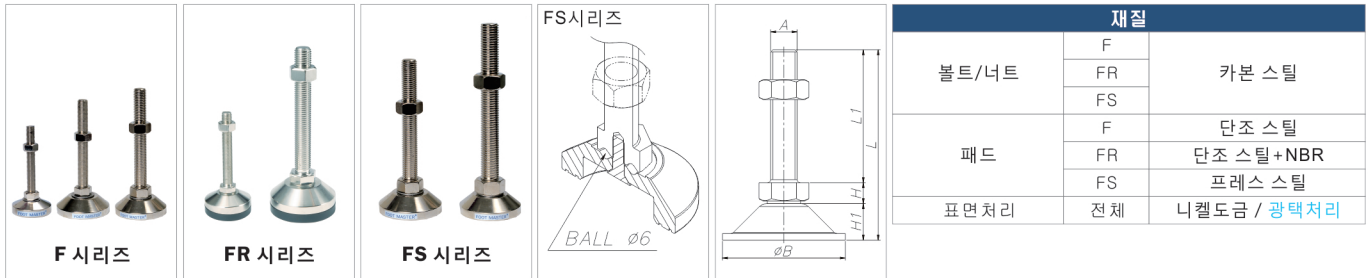

Unit : mm

모델	L1	L	H1	H	B	A	Kg/4개	모델	L1	L	H1	H	B	A	Kg/4개
F-10	60	86	18	8	Ø55	M10x1.5	1,000	FR-10	60	92.5	24.5	8	Ø55	M10x1.5	1,000
	100	126		100					132.5						
F-12	60	87	25	9	Ø80	M12x1.75	1,500	FR-12	60	93.5	35	11	Ø80	M12x1.75	1,500
	90	117							90	123.5					
	120	147							120	153.5					
	150	177							150	183.5					
	180	216							180	226					
F-16 SF-16 (Stainless Steel)	50	86	25	11	Ø80	M16x2.0	2,000	FR-16 SFR-16 (Stainless Steel)	50	96	35	14	Ø80	M16x2.0	2,000
	80	116							80	126					
	100	136							100	146					
	130	166							130	176					
	150	186							150	196					
	180	216							180	226					
F-20 SF-20 (Stainless Steel)	100	139	25	14	Ø80	M20x2.5	3,000	FR-20 SFR-20 (Stainless Steel)	100	149	35	16	Ø80	M20x2.5	3,000
	130	169							130	179					
	150	189							150	199					
	180	219							180	229					
	200	239							200	249					
F-24	150	191	25	16	Ø80	M24x3.0	4,000	FR-24	150	201	35	16	Ø80	M24x3.0	4,000
	200	241							200	251					
모델	L1	L	H1	H	B	A	Kg/4개								
FS-20	150	189	25	13	Ø80	M20x2.5	3,000								
FS-24	200	241	25	15	Ø80	M24x3.0	4,000								