


NEW FLEX Air Hose

E-NF

- E-NF is very light and shows pressure resistance.
- E-NF is made of polyurethane. Thus, even in winter, it keeps higher flexibility.

EIGHTRON

Non-PVC

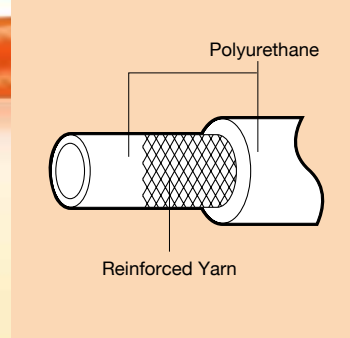

RoHS Compliant

Model Number	I.D. × O.D.		Working Pressure (MPa)		Minimum Bend Radius (20°C)	Temperature Range	Standard Length	Weight	Package Type	Color
	mm		at 20°C	at 60°C						
E-NF-6.5	6.5 × 10	0 ~ 1.5	0 ~ 0.6	40	-20 ~ 60		10	60	Film Wrapping	Orange
							20			
							30			
							50			
E-NF-8.5	8.5 × 12.5	0 ~ 1.5	0 ~ 0.6	55	-20 ~ 60		10	85	Film Wrapping	Orange
							20			
							30			
							50			
E-NF-11	11 × 15.5	0 ~ 1.5	0 ~ 0.6	66	-20 ~ 60		100	125	Paper Bobbin	Orange
							100			

NEW FLEX Push-to-Connect Joint Products

RoHS Compliant



Model Number	Hose Size	Length	Fittings
	I.D. × O.D. (mm)	m	
E-NF-6.5-RC-10M	6.5 × 10	10	E-RSS-65P (Socket) + E-RSP-65P (Plug)
E-NF-6.5-RC-20M		20	
E-NF-6.5-RC-30M		30	
E-NF-8.5-RC-10M	8.5 × 12.5	10	E-RSS-85P (Socket) + E-RSP-85P (Plug)
E-NF-8.5-RC-20M		20	
E-NF-8.5-RC-30M		30	

* NEW FLEX Push-to-Connect Joint Products are available on request. Please contact us for delivery time.

Metal Fittings for NEW FLEX Air Hose

Image	Model Number	Type	Applicable Hose	Thread	Sheet	Material	Weight (g/piece)
	E-EMU-65-G1/4	Female Adaptor (Rotary)	E-NF-6.5	G 1/4	Flat (with Packing)	Brass Nickel Plate	65
	E-EMU-85-G1/4		E-NF-8.5				75
	E-EM-65-G1/4	Female Screw (Fixed)	E-NF-6.5	G 1/4	Male Sheet 30 Degree		55
	E-EM-85-G3/8		E-NF-8.5	G 3/8			80
	E-EO-65-R1/4	Male Screw (Fixed)	E-NF-6.5	R 1/4	—	45	
	E-EO-85-R3/8		E-NF-8.5	R 3/8		80	

*Please refer to page 23 for how to install the metal fittings to the hose.