


■ 육각렌지 ALLOY 12.9 SOCKET HEAD CAP SCREWS(니켈(N), 무전해(E), SUS)

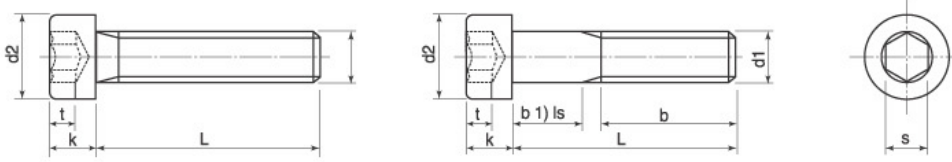

- Material : Steel
- Property class : 12.9
- Tensile strength Rm : 1200Mpa(174000psi)
- Yield strength : 1080Mpa(156600psi)

d1	(*M1.4)	M1.6	(*M1.7)	M2	(*M2.3)	(*M2.5)	(*M2.6)	M3	M4	M5	M6	M8	M10
d2	2.6	3	3.2	3.8	4	4.5	5	5.5	7	8.5	10	13	16
b Nom.length		15		16		17		18	20	22	24	28	32
k	1.4	1.6	1.7	1.5	2.3	2.5	2.6	3	4	5	6	8	10
s	1.3	1.5	1.5	1	2	2	2	2.5	3	4	5	6	8
t min.	0.6	0.7	0.8	11	1.2	1.1	1.2	1.3	2	2.5	3	4	5
Proof load(N)		1210		1970		3200		4880	8520	13800	19500	35500	56300

d1	M12	(M14)	M16	(*M18)	M20	(*M22)	M24	(*M27)	M30	(*M33)	M36	(*M42)	(*M48)
d2	18	21	24	27	30	33	36	40	45	50	54	63	72
b Nom.length	36	40	44)57	48)61	52)65	56)69	60)73	66)79	72)85	78)91	84)97	96)109	108)121
k	12	14	16	18	20	22	24	27	30	33	36	42	48
s	10	12	14	14	17	17	19	19	22	24	27	32	36
t min.	6	7	8	9.8	10	11.3	12	15.1	15.5	18.8	19	25	29.1
Proof load(N)	81800	112000	152000	186000	238000	294000	342000	445000	544000	673000	792000		

DIA 경	LGHT 길이	U / PRICE		DIA 경	LGHT 길이	U / PRICE		DIA 경	LGHT 길이	U / PRICE	
		BOX	가 격			BOX	가 격			BOX	가 격
M 1.6	x 3			M 2.5	x 3			M 3	x 4		
	x 4				x 4				x 5		
	x 5				x 5				x 6		
	x 6				x 6				x 8		
	x 8				x 8				x 10		
	x 10				x 10				x 12		
M 2	x 3				x 12				x 14		
	x 4				x 15				x 15		
	x 5				x 18				x 16		
	x 6				x 20				x 18		
	x 8			x 25			x 20				
	x 10			x 4			x 22				
	x 12			x 5			x 25				
	x 15			x 6			x 30				
x 18			M 2.6	x 8			x 35				
x 20				x 10			x 40				
M 2.3	x 4				x 12				x 45		
	x 5				x 15				x 50		
	x 6				x 18				x 55		
	x 8				x 20				x 60		
	x 10										

※ 주문 예) : 12.9 S.H.C.S M2x6(E)