


■ 동근머리렌지 ALLOY 10.9 STEELBUTTON HEAD CAP SCREWS(니켈(N), 무전해(E), SUS)

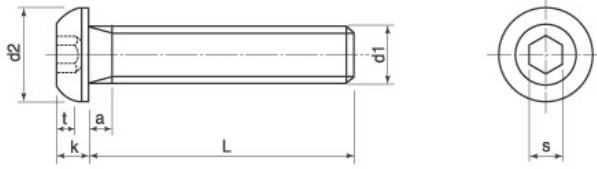

- Material : Steel
- Property class : 10.9

d1	M2	M2.5	M3	M4	M5	M6	M8	M10	M12
d2 max	3.7	4.6	(*5.7)5.5	(*7.6)7.5	9.5	10.5	14	(*17.5)18	21
k max	1.2	1.5	1.65	1.65	2.75	3.3	4.4	5.5	6.6
s	1	1.5	2	2	3	4	5	6	8
t min	0.8	1	1.04	1.04	1.56	2.08	2.60	3.12	4.16

DIA 경	LGHT 길이	U / PRICE		DIA 경	LGHT 길이	U / PRICE		DIA 경	LGHT 길이	U / PRICE	
		BOX	가 격			BOX	가 격			BOX	가 격
M 2	x 3			M 4	x 5			M 6	x 8		
	x 4				x 6				x 10		
	x 5				x 8				x 12		
	x 6				x 10				x 16		
	x 8				x 12				x 18		
	x 10				x 16				x 20		
M 2.5	x 4			x 18			x 22				
	x 5			x 20			x 25				
	x 6			x 22			x 30				
	x 8			x 25			x 35				
	x 10			x 30			x 40				
M 3	x 4			M 5	x 6			M 8	x 45		
	x 5				x 8				x 50		
	x 6				x 10				x 10		
	x 8				x 12				x 12		
	x 10				x 16				x 16		
	x 12				x 18				x 18		
	x 15				x 20				x 20		
	x 16				x 22				x 25		
	x 18				x 25				x 30		
	x 20				x 30				x 35		
	x 22				x 35			x 40			
	x 25				x 40			x 45			
x 30			x 50			x 50					

※ 주문 예) : 10.9 B.H.C.S M3x12(N)