


■ 쇼일더렌지볼트 ALLOY 12.9 HEX SHOULDER SCREWS

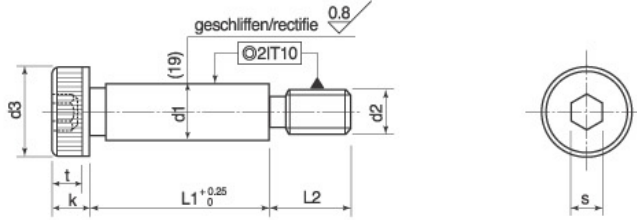

- Material : Steel
- Property class : 12.9

d1 Nom.dia	6	6.5*	8	10	12	13*	16	20	24	25*
max	5.990	6.487	7.987	9.987	11.984	12.984	15.984	19.980	23.980	24.980
min	5.960	6.451	7.951	9.951	11.941	12.941	15.941	19.928	23.928	24.928
d2	M5	M5	M16	M8	M10	M12	M12	M16	M20	M20
2it 10	0.12	0.12	0.12	0.12	0.14	0.14	0.14	0.14	0.17	0.17
d3	10	10	13	16	18	24	24	30	36	36
k max	4.5	4.5	5.5	7	9	10	10	14	16	16
t min	2.4	2.4	3.3	4.2	4.9	6.6	6.6	8.8	10	10
L2	9.5	9.75	11	13	16.4	18	18	22	27	27.4
s	3	3	4	5	6	8	8	10	12	12

DIA 경	LGHT 길이	U / PRICE		DIA 경	LGHT 길이	U / PRICE		DIA 경	LGHT 길이	U / PRICE	
		BOX	가 격			BOX	가 격			BOX	가 격
ø 6 x (M5)	x 10			ø 10 x (M8)	x 50			ø 16 x (M12)	x 90		
	x 12				x 60				x 100		
	x 16				x 70				x 110		
	x 20				x 80				x 120		
	x 25			ø 12 x (M10)	x 15			ø 20 x (M16)	x 40		
	x 30				x 20				x 50		
	x 35				x 25				x 60		
	x 40				x 30				x 70		
ø 8 x (M6)	x 12				x 35				x 80		
	x 16				x 40				x 90		
	x 20				x 50				x 100		
	x 25				x 60				x 110		
	x 30			x 70			x 120				
	x 35			x 80			ø 24 x (M20)	x 50			
	x 40			x 90				x 60			
	x 50			x 100				x 70			
ø 10 x (M8)	x 12			ø 16 x (M12)	x 30				x 80		
	x 16				x 35			x 90			
	x 20				x 40			x 100			
	x 25				x 50			x 110			
	x 30				x 60			x 120			
	x 35				x 70						
	x 40				x 80						

※ 주문 예) : SHOULDER M5x30(M=D2, 30:L1) / SHOULDER ø6x30(ø6:M5, 30:L1)