
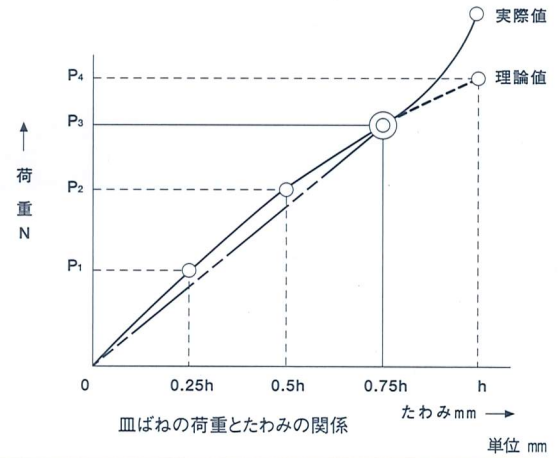


MDS皿ばね

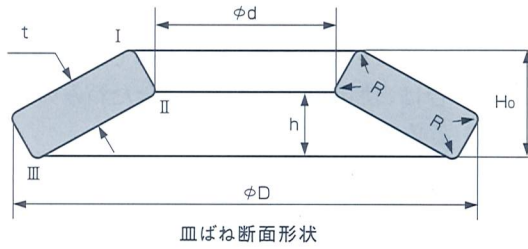

MDS製品規格

呼び	基本寸法						荷重 N				応力 MPa		
	d	D	t	h	H ₀	h/t	P1	P2	P3	P4	σ _{II} または σ _{III}		
							δ=0.25h	δ=0.50h	δ=0.75h	δ=h	δ=0.50h	δ=0.75h	δ=h
3-1	3.2	6.0	0.20	0.20	0.40	1.00	29.1	48.4	61.0	70.3	985	1366	1673
3-2		6.0	0.30	0.15	0.45	0.50	55.0	103.0	136.0	178.0	909	1200	1765
3-3		8.0	0.20	0.20	0.40	1.00	13.5	22.4	28.2	32.5	439	608	743
3-4		8.0	0.30	0.25	0.55	0.83	48.2	89.0	115.0	137.0	786	1072	1428
4-1	4.2	8.0	0.30	0.25	0.55	0.83	55.7	103.0	133.0	158.0	977	1334	1632
4-2		8.0	0.40	0.20	0.60	0.50	87.5	164.0	234.0	301.0	843	1227	1763
4-3		10.0	0.30	0.35	0.65	1.17	59.5	94.4	112.0	123.0	839	1119	1366
4-4		10.0	0.40	0.30	0.70	0.75	90.5	151.0	207.0	250.0	769	1098	1513
5-1	5.2	10.0	0.40	0.30	0.70	0.75	101.0	170.0	232.0	280.0	919	1313	1602
5-2		10.0	0.50	0.25	0.75	0.50	128.0	258.0	360.0	456.0	864	1247	1762
5-3		12.0	0.40	0.40	0.80	1.00	95.9	159.0	201.0	232.0	823	1139	1393
5-4		12.0	0.50	0.40	0.90	0.80	161.0	280.0	373.0	452.0	934	1306	1678
6-1	6.2	12.5	0.50	0.35	0.85	0.70	141.0	252.0	333.0	416.0	818	1114	1401
6-2		12.5	0.70	0.30	1.00	0.43	291.0	522.0	769.0	978.0	871	1430	1973
6-3		15.0	0.50	0.50	1.00	1.00	157.0	253.0	321.0	368.0	797	1114	1349
6-4		15.0	0.70	0.40	1.10	0.57	245.0	453.0	636.0	807.0	736	1211	1756
7-1	7.2	14.0	0.50	0.40	0.90	0.80	136.0	238.0	316.0	383.0	792	1109	1373
7-2		14.0	0.80	0.30	1.10	0.38	342.0	620.0	921.0	1180.0	832	1351	1849
7-3		18.0	0.50	0.60	1.10	1.20	145.0	230.0	274.0	299.0	711	976	1181
7-4		18.0	0.80	0.45	1.25	0.56	271.0	523.0	726.0	917.0	690	1113	1595
8-1	8.2	16.0	0.60	0.45	1.05	0.75	188.0	345.0	459.0	560.0	811	1124	1387
8-2		16.0	0.90	0.35	1.25	0.39	415.0	797.0	1120.0	1470.0	852	1296	1844
8-3		20.0	0.60	0.70	1.30	1.17	236.0	369.0	445.0	488.0	807	1117	1345
8-4		20.0	0.90	0.55	1.45	0.61	409.0	749.0	1020.0	1290.0	736	1162	1712
9-1	9.2	18.0	0.70	0.50	1.20	0.71	266.0	459.0	630.0	770.0	798	1134	1397
9-2		18.0	1.00	0.40	1.40	0.40	496.0	952.0	1380.0	1800.0	820	1305	1839
9-3		23.0	0.70	0.70	1.40	1.00	244.0	396.0	503.0	577.0	651	908	1101
9-4		23.0	1.00	0.60	1.60	0.60	445.0	818.0	1140.0	1440.0	661	1094	1594
10-1	10.2	20.0	0.80	0.55	1.35	0.69	337.0	605.0	812.0	1010.0	812	1121	1405
10-2		20.0	1.00	0.55	1.55	0.55	603.0	1120.0	1550.0	1980.0	942	1310	1882
10-3		25.0	0.80	0.85	1.65	1.06	382.0	635.0	783.0	886.0	804	1103	1339
10-4		25.0	1.00	0.75	1.75	0.75	529.0	934.0	1240.0	1530.0	764	1055	1530