

T-너트 >마름모-반가공상태<

EH 23020.




제품 설명


재질

- 열처리 스틸, 밝은색

그림

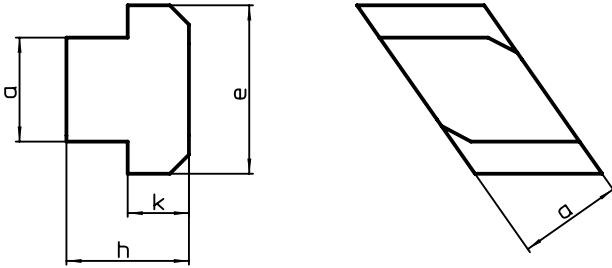

주문 정보

T-슬롯 사이즈 [mm]	a	e	치수 [mm]	h	k	 [g]	부품번호.
6	5,7	10		8	4	3	23020.0561
8	7,6	13		10	6	7	23020.0581
10	9,6	15		12	6	13	23020.0601
12	11,6	18		14	7	21	23020.0621
14	13,6	22		16	8	35	23020.0641
16	15,6	25		18	9	52	23020.0661
18	17,6	28		20	10	73	23020.0681
20	19,6	32		24	12	110	23020.0701
22	21,6	35		28	14	159	23020.0721
28	27,6	44		36	18	313	23020.0781
36	35,5	54		44	22	638	23020.0861