




제품 설명

재질

- 열처리 스틸, 담금질, 흑색처리

그림

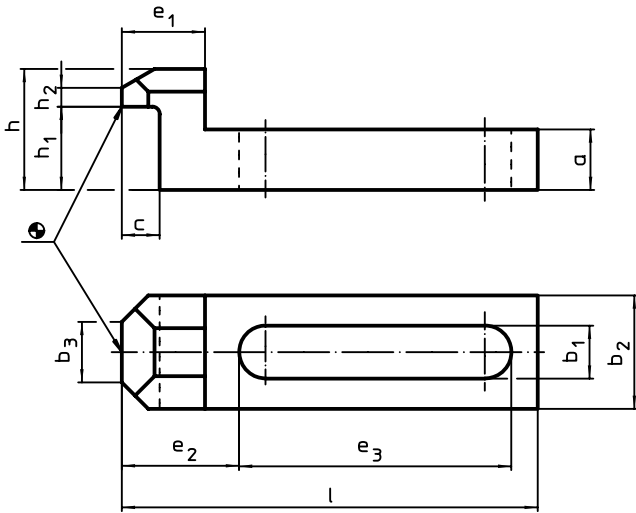

주문 정보

기본 치수 b ₁ [mm]	l	a	b ₂	b ₃	c	치수 [mm]						스크류용		부품번호	
						e ₁	e ₂	e ₃	h	h ₁	h ₂	[mm]	[인치 (inch)]		[g]
6,6	55	8	15	8	5	11	15,5	36	16	11	2	M 6	1/4	39	23160.0107
9,0	70	10	20	10	8	15	19,5	46	20	14	3	M 8	5/16	80	23160.0109
11,0	90	13	25	12	10	19	26,5	58	25	18	4	M10	3/8	170	23160.0111
13,0	115	16	30	15	12	24	32,5	75	32	23	5	M12	1/2	328	23160.0113
17,0	145	20	40	20	14	29	38,5	99	40	28	6	M16	5/8	685	23160.0117

적용 예

