
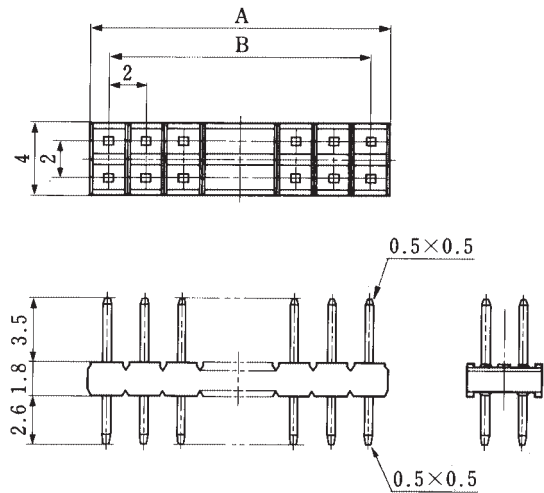



■ピンヘッダー

●A3Bストレートタイプ

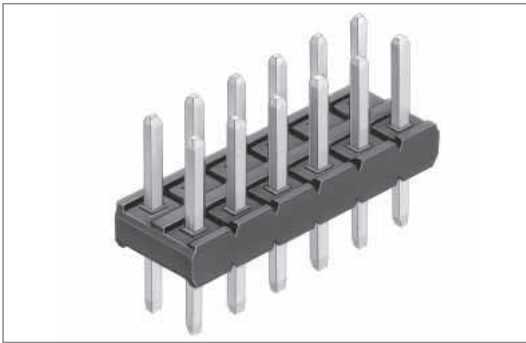


製品番号	HRS No.	極数	A	B	RoHS
A3B- 4PA-2DSA(71)	CL621-0401-1-71	4	4.0	2.0	○
A3B- 6PA-2DSA(71)	CL621-0402-4-71	6	6.0	4.0	
A3B- 8PA-2DSA(71)	CL621-0403-7-71	8	8.0	6.0	
A3B-10PA-2DSA(71)	CL621-0404-0-71	10	10.0	8.0	
A3B-12PA-2DSA(71)	CL621-0405-2-71	12	12.0	10.0	
A3B-14PA-2DSA(71)	CL621-0406-5-71	14	14.0	12.0	
A3B-16PA-2DSA(71)	CL621-0407-8-71	16	16.0	14.0	
A3B-18PA-2DSA(71)	CL621-0408-0-71	18	18.0	16.0	
A3B-20PA-2DSA(71)	CL621-0409-3-71	20	20.0	18.0	
A3B-22PA-2DSA(71)	CL621-0410-2-71	22	22.0	20.0	
A3B-24PA-2DSA(71)	CL621-0411-5-71	24	24.0	22.0	
A3B-26PA-2DSA(71)	CL621-0412-8-71	26	26.0	24.0	
A3B-28PA-2DSA(71)	CL621-0413-0-71	28	28.0	26.0	
A3B-30PA-2DSA(71)	CL621-0414-3-71	30	30.0	28.0	
A3B-32PA-2DSA(71)	CL621-0415-6-71	32	32.0	30.0	


 
(注) ご注文は100個単位でお願いします。



◆推奨基板寸法図

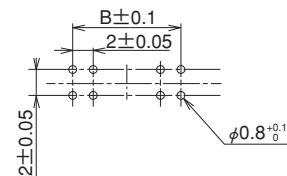


●A3Bライトアングルタイプ

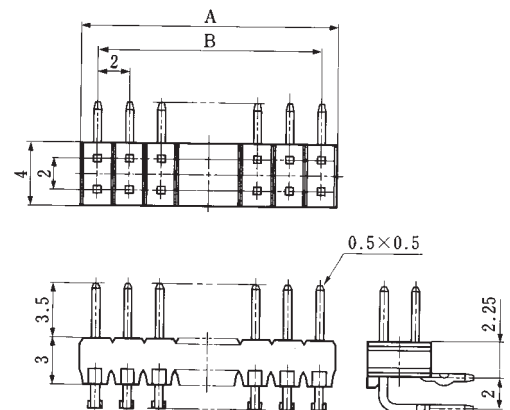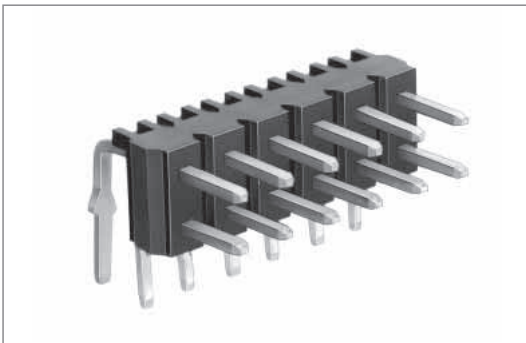

製品番号	HRS No.	極数	A	B	キンク位置(注1)	RoHS
A3B- 4PA-2DS(71)	CL621-0351-5-71	4	4.0	2.0	2本	○
A3B- 6PA-2DS(71)	CL621-0352-8-71	6	6.0	4.0	1端子おき1本又は2本	
A3B- 8PA-2DS(71)	CL621-0353-0-71	8	8.0	6.0	1端子おき2本	
A3B-10PA-2DS(71)	CL621-0354-3-71	10	10.0	8.0	1端子おき2本又は3本	
A3B-12PA-2DS(71)	CL621-0355-6-71	12	12.0	10.0	1端子おき3本	
A3B-14PA-2DS(71)	CL621-0356-9-71	14	14.0	12.0	1端子おき3本又は4本	
A3B-16PA-2DS(71)	CL621-0357-1-71	16	16.0	14.0	1端子おき4本	
A3B-18PA-2DS(71)	CL621-0358-4-71	18	18.0	16.0	1端子おき4本又は5本	
A3B-20PA-2DS(71)	CL621-0359-7-71	20	20.0	18.0	1端子おき5本	
A3B-22PA-2DS(71)	CL621-0360-6-71	22	22.0	20.0	1端子おき5本又は6本	
A3B-24PA-2DS(71)	CL621-0361-9-71	24	24.0	22.0	1端子おき6本	
A3B-26PA-2DS(71)	CL621-0362-1-71	26	26.0	24.0	1端子おき6本又は7本	
A3B-28PA-2DS(71)	CL621-0363-4-71	28	28.0	26.0	1端子おき7本	
A3B-30PA-2DS(71)	CL621-0364-7-71	30	30.0	28.0	1端子おき7本又は8本	
A3B-32PA-2DS(71)	CL621-0365-0-71	32	32.0	30.0	1端子おき8本	
A3B-44PA-2DS(71)	CL621-0377-9-71	44	44.0	42.0	1端子おき11本	
A3B-50PA-2DS(71)	CL621-0383-1-71	50	50.0	48.0	1端子おき12本又は13本	

(注1) ご注文は100個単位でお願いします。

(注2) 28極以上はφ0.95±0.04となります。

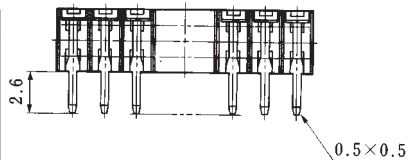

◆推奨基板寸法図(t=1.6)

