
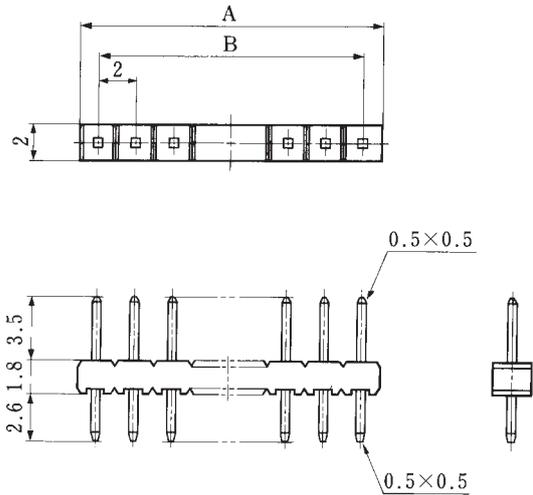



●A4Bストレートタイプ

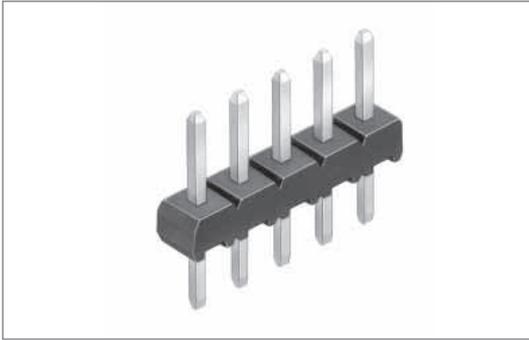


製品番号	HRS No.	極数	A	B	RoHS
A4B- 2PA-2DSA(71)	CL622-0401-8-71	2	4.0	2.0	○
A4B- 3PA-2DSA(71)	CL622-0402-0-71	3	6.0	4.0	
A4B- 4PA-2DSA(71)	CL622-0403-3-71	4	8.0	6.0	
A4B- 5PA-2DSA(71)	CL622-0404-6-71	5	10.0	8.0	
A4B- 6PA-2DSA(71)	CL622-0405-9-71	6	12.0	10.0	
A4B- 7PA-2DSA(71)	CL622-0406-1-71	7	14.0	12.0	
A4B- 8PA-2DSA(71)	CL622-0407-4-71	8	16.0	14.0	
A4B- 9PA-2DSA(71)	CL622-0408-7-71	9	18.0	16.0	
A4B-10PA-2DSA(71)	CL622-0409-0-71	10	20.0	18.0	
A4B-12PA-2DSA(71)	CL622-0411-1-71	12	24.0	22.0	
A4B-13PA-2DSA(71)	CL622-0412-4-71	13	26.0	24.0	
A4B-14PA-2DSA(71)	CL622-0413-7-71	14	28.0	26.0	
A4B-15PA-2DSA(71)	CL622-0414-0-71	15	30.0	28.0	
A4B-16PA-2DSA(71)	CL622-0415-2-71	16	32.0	30.0	

(注) ご注文は100個単位でお願いします。

 ◆推奨基板寸法図



●A4Bライトアングルタイプ

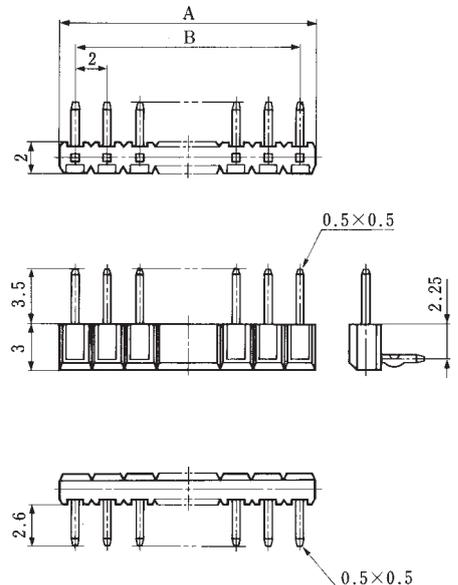

製品番号	HRS No.	極数	A	B	キンク位置(注1)	RoHS
A4B- 2PA-2DS(71)	CL622-0351-1-71	2	4.0	2.0	2本	○
A4B- 3PA-2DS(71)	CL622-0352-4-71	3	6.0	4.0	1端子おき1本又は2本	
A4B- 4PA-2DS(71)	CL622-0353-7-71	4	8.0	6.0	1端子おき2本	
A4B- 5PA-2DS(71)	CL622-0354-0-71	5	10.0	8.0	1端子おき2本又は3本	
A4B- 6PA-2DS(71)	CL622-0355-2-71	6	12.0	10.0	1端子おき3本	
A4B- 7PA-2DS(71)	CL622-0356-5-71	7	14.0	12.0	1端子おき3本又は4本	
A4B- 8PA-2DS(71)	CL622-0357-8-71	8	16.0	14.0	1端子おき4本	
A4B- 9PA-2DS(71)	CL622-0358-0-71	9	18.0	16.0	1端子おき4本又は5本	
A4B-10PA-2DS(71)	CL622-0359-3-71	10	20.0	18.0	1端子おき5本	
A4B-11PA-2DS(71)	CL622-0360-2-71	11	22.0	20.0	1端子おき5本又は6本	
A4B-12PA-2DS(71)	CL622-0361-5-71	12	24.0	22.0	1端子おき6本	
A4B-13PA-2DS(71)	CL622-0362-8-71	13	26.0	24.0	1端子おき6本又は7本	
A4B-14PA-2DS(71)	CL622-0363-0-71	14	28.0	26.0	1端子おき7本	
A4B-15PA-2DS(71)	CL622-0364-3-71	15	30.0	28.0	1端子おき7本又は8本	
A4B-16PA-2DS(71)	CL622-0365-6-71	16	32.0	30.0	1端子おき8本	

(注1) ご注文は100個単位でお願いします。

(注2) 14極以上はφ0.95±0.04となります。

◆推奨基板寸法図(t=1.6)

