


■レセプタクルコネクタ



●偏心度0.9mmタイプ

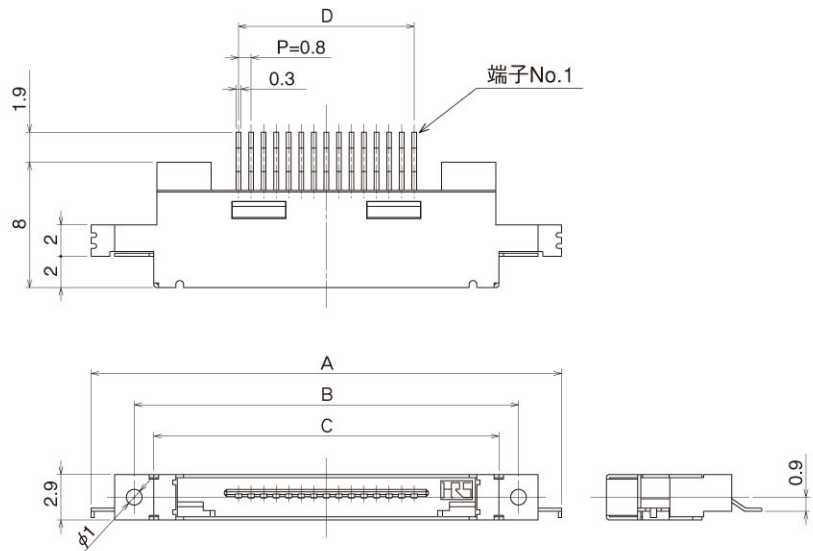

単位：mm

製品番号	HRS No.	極数	A	B	C	D	RoHS
NX60TB-15SAA9-SP(50)	CL234-0097-6-50	15	30.0	24.5	22.0	11.2	○
NX60TA-25SAA9-SP(50)	CL234-0107-8-50	25	38.0	32.5	30.0	19.2	
NX60T-32SAA9-SP(50)	CL234-0023-0-50	32	43.6	38.1	35.6	24.8	

●偏心度0.3mmタイプ

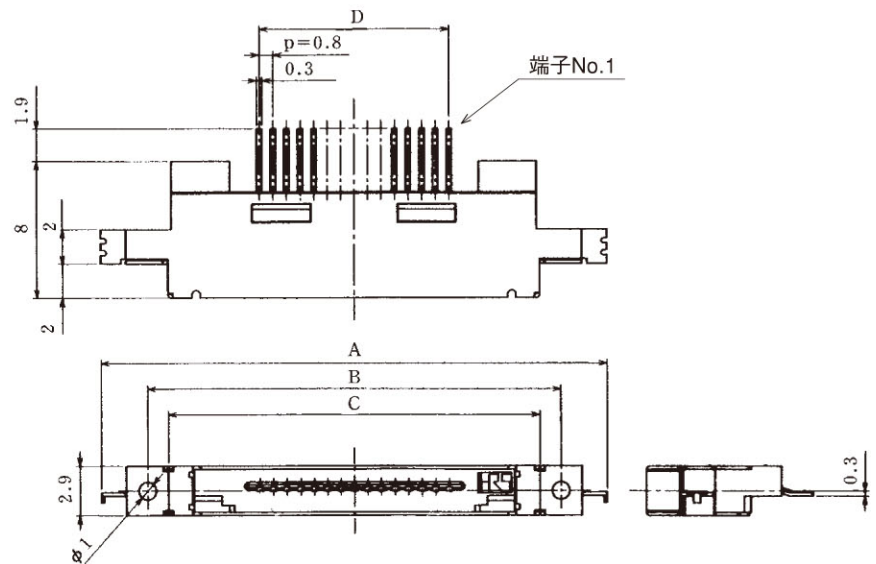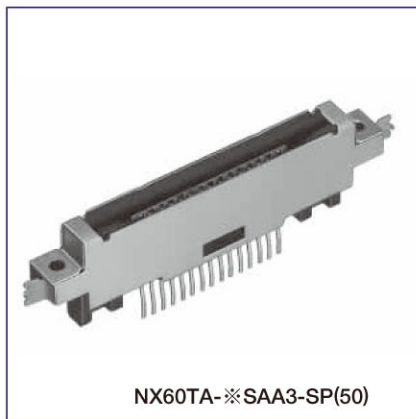

単位：mm

製品番号	HRS No.	極数	A	B	C	D	RoHS
NX60TB-15SAA3-SP(50)	CL234-0098-9-50	15	30.0	24.5	22.0	11.2	○
NX60TA-25SAA3-SP(50)	CL234-0033-3-50	25	38.0	32.5	30.0	19.2	
NX60TA-32SAA3-SP(50)	CL234-0053-0-50	32	43.6	38.1	35.6	24.8	