


めすアダプタソケット

(PQWK-ZFS)

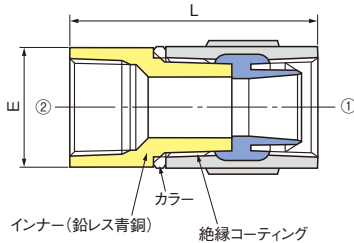


(単位:mm)

呼び	E(二面幅)		L	ねじ①②
	六角	八角		
1/2	29	—	59.5	Rc1/2
3/4	32.5	—	65.5	Rc3/4
1	39.5	—	75	Rc1
1 1/4	48.3	—	84	Rc1 1/4
1 1/2	56	—	93	Rc1 1/2
2	—	68	101	Rc2

径違いめすアダプタソケット

(PQWKZFRS)


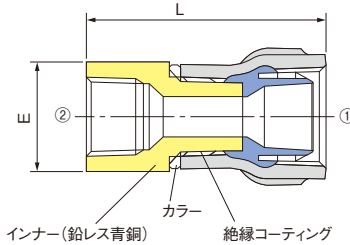


(単位:mm)

呼び	E(二面幅)	L	ねじ①	ねじ②
	六角			
3/4 x 1/2	29	62.5	Rc3/4	Rc1/2

めすアダプタチー

(PQWK-ZFT)

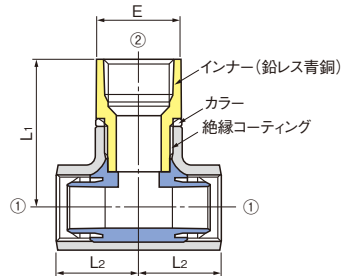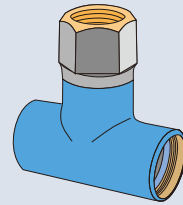


(単位:mm)

呼び	E(二面幅)	L1	L2	ねじ①②
	六角			
1/2	29	51.5	27	Rc1/2
3/4	32.5	57.5	32.5	Rc3/4

径違いめすアダプタチー

(PQWKZFRT)

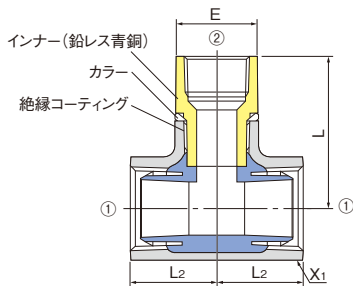



(単位:mm)

呼び	E(二面幅)	L1	L2	ねじ①	ねじ②
	六角				
3/4 x 1/2	29	54	29	Rc3/4	Rc1/2
1 x 1/2	29	57	32	Rc1	Rc1/2
1 x 3/4	32.5	60	34	Rc1	Rc3/4

ZC形

給水栓エルボ

(PQWKZCL)

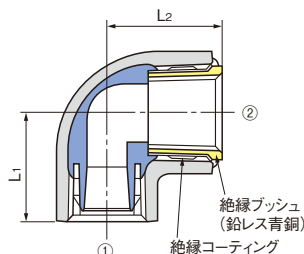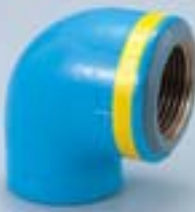


(単位:mm)

呼び	L1	L2	ねじ①②
1/2	30	32	Rc1/2
3/4	35	37	Rc3/4
1	42	43	Rc1

径違い給水栓エルボ

(PQWKZCRL)

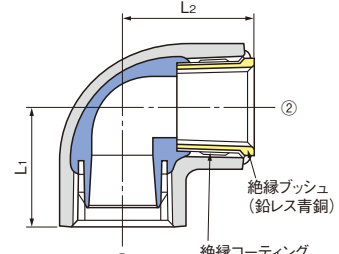

(単位:mm)

呼び	L1	L2	ねじ①	ねじ②
3/4 x 1/2	32	35	Rc3/4	Rc1/2
1 x 1/2	34	38	Rc1	Rc1/2
1 x 3/4	38	41	Rc1	Rc3/4

禁止：ZC形の器具接続側にはパイプレンチ等の工具は使用しないでください。