



SEN END FITTING

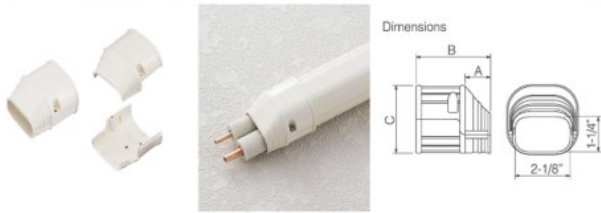

Code No.	Item No.	A	B	C	Pcs/Pkg
C 0488	SEN-100	2-1/4"	4-1/2"	3"	20
C 0489	SEN-140	3-1/8"	6"	3-3/8"	10


SWC WALL FLANGE

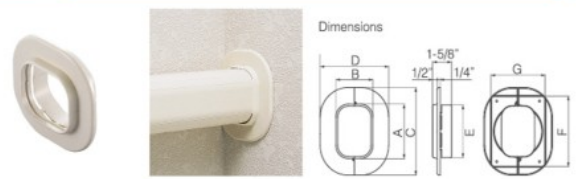

Code No.	Item No.	A	B	C	D	E	F	G	Diameter of core drill	Pcs/Pkg
C 0482	SWC-77	3-3/8"	2-7/8"	5"	4-5/8"	3-1/4"	4-3/8"	3-5/8"	3-3/8"	100
C 0483	SWC-100	4-3/8"	3-1/8"	6-7/8"	5-3/4"	4-1/8"	5-5/8"	4-1/2"	4-3/8"	50
C 0484	SWC-140	5-7/8"	3-1/2"	8-3/4"	7-1/8"	5-3/4"	7-3/4"	6-1/8"	5-3/4"	20

Material ... ABS


SP SOFFIT INLET

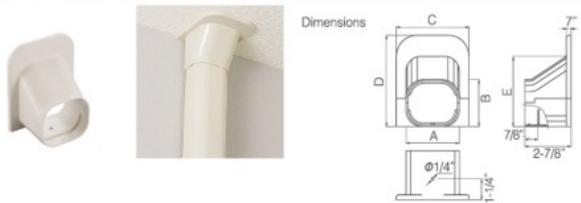

Code No.	Item No.	A	B	C	D	E	Pcs/Pkg
C 7342	SP-77	3-1/4"	2-3/4"	4-3/8"	5-1/8"	4"	20
C 7343	SP-100	4-1/4"	3"	5-3/8"	5-1/2"	4-1/4"	10
C 7344	SP-140	5-3/4"	3-3/8"	7"	5-7/8"	4-5/8"	5

Material ... ABS


SF FLEXIBLE ELL with End Cuffs

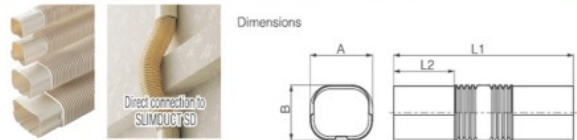

Code No.	Item No.	A	B	L1	L2	Pcs/Pkg
C 0453	SF-77-500	3"	2-1/2"	20-7/8"	3-1/2"	20
C 0454	SF-77-1000	3"	2-1/2"	41-3/4"	3-1/2"	20
C 0455	SF-100-800	4"	2-7/8"	31-1/2"	2-7/8"	10
C 0456	SF-140-800	5-5/8"	3-1/4"	31-1/2"	3-1/4"	5

Material ... PE (77), PP (100/140)


SFS SADDLE for FLEXIBLE ELL SF

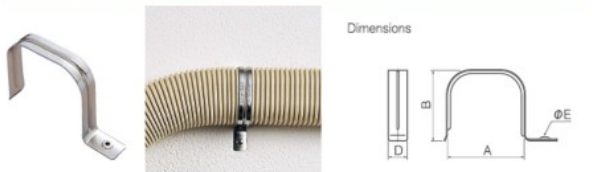

Code No.	Item No.	A	B	D	E	Pcs/Pkg
C 0612	SFS-77	3"	2-1/2"	3/4"	1/4"	60
C 0613	SFS-100	4"	2-7/8"	7/8"	3/8"	40
C 0614	SFS-140	5-3/4"	3-3/8"	7/8"	3/8"	40

Material ... SUS304

SF 2M (78-3/4") FLEXIBLE ELL without End Cuffs

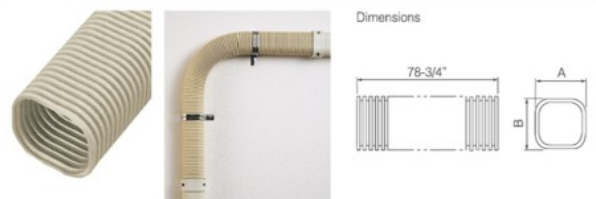

Code No.	Item No.	A	B	Pcs/Pkg
C 0460	SF-77-2000	3"	2-1/2"	10

Material ... PE *Use only in conjunction with SFJ Coupler and SFS Clamp.

SFJ SF FLEXIBLE ADAPTOR



Code No.	Item No.	A	B	C	Pcs/Pkg
C 0437	SFJ-77	3-3/8"	2-5/8"	1-1/2"	20
C 0438	SFJ-100	4-3/8"	3"	1-5/8"	20

* Use in combination with SFS.


* For secure joint, insert 2 corrugations of SF into SFJ adaptor.

Caution


- SLIMDUCT SD is NOT WATERPROOF. To waterproof, seal all longitudinal and lateral seams, screw heads and wall penetration with weatherproof sealant or putty.
- SLIMDUCT SD duct and fittings are suitable for use and storage within a temperature range of -4°F to 140°F. Deformation may occur at temperatures exceeding 140°F. Protect SLIMDUCT installation from direct and radiant heat.
- When attaching SLIMDUCT to wall, use only pan head screws. Do not use flat head or countersunk screws as they can exert too much pressure and crack the PVC material.
- Use of impact screwdrivers to attach SLIMDUCT to wall and to tighten fixing screws on fittings is highly discouraged as they can easily overtighten the screws and crack the PVC material. Use hand screwdrivers for precise torque control.
- Use SL-300 STRAP KIT to retain lineset inside duct.
- For further information, refer to SLIMDUCT SD Installation Manual.

Application Example for FLEXIBLE ELL

Vertical Application

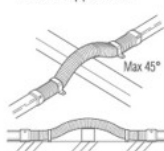

Horizontal Application

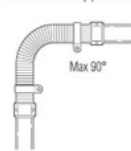


DO NOT BEND OVER PARAPET



DO NOT BEND MORE THAN 90°



SL STRAP KIT For SLIMDUCT

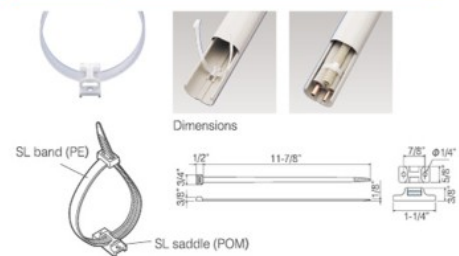

Code No.	Item No.	Pcs/Pkg
C 04720	SL-300	500

Material ... PE (SL band), POM (SL saddle)

*Do not overtighten strap! That may decrease insulation performance.