


Use exclusively with INABA DENKO Drain Hose.

DS SADDLE

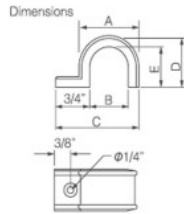


- Features**
- Attractive, compact, quick fitting.
 - Weather resistant.
 - Ivory color matches DRAIN HOSE.
 - Appearance matches SLIMDUCT SD.

- Specifications**
- Material ... PP
 - Color ... Ivory

Code No.	Item No.	Compliant drain hose	A	B	C	D	E	Pcs/Pkg
C 08142	DS-14	DH-14, DHQ-14	1-1/8"	3/4"	1-5/8"	1"	3/4"	500
C 08152	DS-16	DH-16, DHQ-16	1-1/4"	7/8"	1-3/4"	1"	7/8"	500

DHB MINI INLINE TRAP

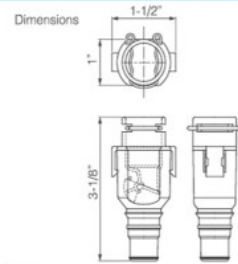

- Application**
- In an airtight home, pressure difference between indoors and outdoors may cause air backflow and result in noise. DHB Trap promotes condensate flow thus preventing noise and deters insects from entering DRAIN HOSE.


- Features**
- Transparent body permits easy inspection.
 - Weather resistant plastic requires no protection.
 - Easy for maintenance work.
 - Accepts DHQ 14 & DHQ 16 without adaptor.

- Caution**
- This product does not produce a 100% seal. Under extremely high negative pressure conditions inside the building, some outside air may be admitted.
 - Use tape to connect DHB to DRAIN HOSE.

- Specifications**
- Material ... Acrylic resin
 - Color ... Transparent

Code No.	Item No.	Compliant drain hose	Pcs/Pkg
C 08110	DHB-1416	DHQ-14, DHQ-16	50

DC BUG STOPPER

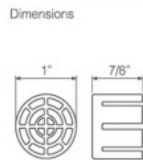

Application




- Features**
- Prevents insects from entering DRAIN HOSE.
 - Clips easily onto O.D. of DRAIN HOSE.
 - Fits both 1/2" & 5/8" hose.

- Specifications**
- Material ... PP
 - Color ... Ivory

Code No.	Item No.	Compliant drain hose	Pcs/Pkg
C 08050	DC-1416	DH-14, DHQ-14 DH-16, DHQ-16	50sets (2 pcs/set)

DL DRAIN CHANNEL

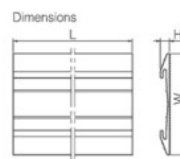


- Features**
- Eliminates wet floors and prevents formation of dirt accumulations by leading condensate directly to drainage point.
 - Gray color easily blends in with concrete flooring material.
 - Easy to cut by knife or scissors.

- Specifications**
- Material ... PVC
 - Color ... Gray
 - Temperature Range ... -4°F - 140°F


* Requires cement/glue to stick permanently onto floor.
* Use in combination with DRAIN CHANNEL ADAPTOR (DL-H).

Code No.	Item No.	Length(L)(ft)	Width(W)	Height(H)	Pcs/Pkg
C 23411	DL-25	82'	2-1/4"	1/4"	1

DL-H DRAIN CHANNEL ADAPTOR

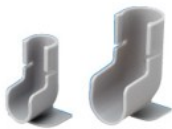

DL-H13 DL-H20

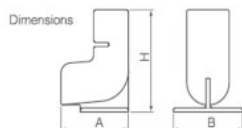

- Specifications**
- Material ... PVC
 - Color ... Gray
 - Temperature Range ... -4°F - 140°F

- Features**
- Clips end of DRAIN HOSE into DRAIN CHANNEL without cement/glue.

Code No.	Item No.	Compliant pipe	A	B	H	Pcs/Pkg
C 23421	DL-H13	DH-14, DHQ-14 DH-16, DHQ-16	1-1/2"	1-1/2"	2"	100
C 23431	DL-H20	PVC pipe 3/4"	2"	1-1/2"	2-5/8"	100

PMD INSULATION for Drain Hose



- Application**
- Insulation material for Drain Hose.

- Specifications**
- Material ... Polyethylene foam (conforms to JIS A9511 A-PE-C-2)

- Caution**
- Insert Drain Hose before installation.
 - Fasten the connection part by such as tape to the drain hose affiliated with AC unit.

Code No.	Item No.	Inside Diameter	Insulation Thickness	Length	Pcs/Pkg
C 16901	PMD	1"	3/16"	79-3/4"	100