


SADDLE

KS

SINGLE SADDLE (for A/C Refrigerant Piping)



Dimensions

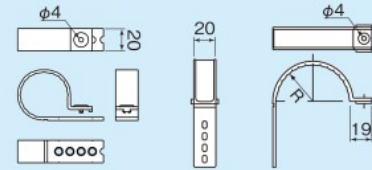

Unit : mm

Specifications ● Material ... PE

Code No.	Item No.	Effective Inside Diameter	Color	Pcs/Pkg
☑ 05012	KS-20-I	φ39 ~ φ45	Ivory	1000
☑ 05102	KS-24-I	φ38 ~ φ50	Ivory	500


VES

DOUBLE SADDLE

Saddle for VE Pipe and Insulated Drain Pipe



Dimensions

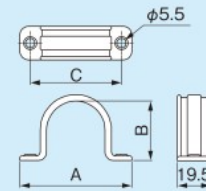

Unit : mm

Specifications ● Material ... PP (Indoor use)
● Color ... Ivory

Code No.	Item No.	A	B	C	Compliant NDD Size	Pcs/Pkg
☑ 06572	VES-28N-I	65	34.5	53	NDD-20	200
☑ 05030	VES-36-I	97	42	73.5	NDD-25	200
☑ 05040	VES-42-I	107	48	83.5	-	200


VS

DOUBLE SADDLE

Saddle for VP Pipe



Dimensions

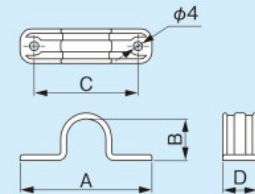

Unit : mm

Specifications ● Material ... PP (Indoor use)
● Color ... Ivory

Code No.	Item No.	A	B	C	D	Compliant ND Size	Pcs/Pkg
☑ 06532	VS-14	57	18	45	15	ND-14	500
☑ 06542	VS-16	61	22	47	15	ND-16	500
☑ 06552	VS-22	65	26	53	18	ND-20	300
☑ 06562	VS-25	71	32	57	18	ND-25	300

DSV

SINGLE SADDLE


Saddle for VP Pipe



Specifications

- Material ... PP (Indoor use)
- Color ... Ivory

Dimensions

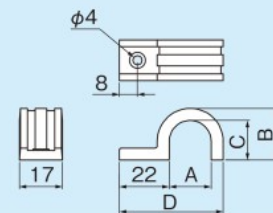

Unit : mm

Code No.	Item No.	Compliant ND Size	A	B	C	D	Pcs/Pkg
☑ 06700	DSV-14	ND-14	18.3	22	17.5	45	500
☑ 06710	DSV-16	ND-16	22.3	26	21.5	49	500


DS

DRAIN HOSE SADDLE

Saddle for DRAIN HOSE



Dimensions

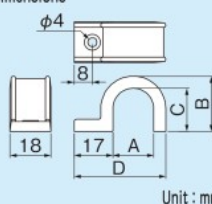

Unit : mm

Specifications ● Material ... PP (Indoor use)
● Color ... Ivory

Features

- Exclusive use for drain hose - attractive, compact and quick fitting!
- Much easier installation than conventional product.
- Superior in weather resistant and ivory color never spoil beautiful appearance.
- Really compact due to exclusive use for drain hose.
- Useful for more beautiful appearance by combination with SLIMDUCT SD/NSD.

Code No.	Item No.	Compliant Drain Hose	A	B	C	D	Pcs/Pkg
☑ 08142	DS-14-I	DH-14-DHQ-14	18	24	19	39.3	500
☑ 08152	DS-16-I	DH-16-DHQ-16	20	26	21	41.3	500