
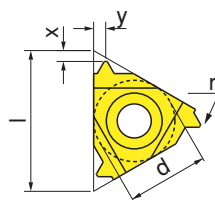


NPTねじ切りチップ(NPT) BSPTねじ切りチップ(BSPT)仕上刃(さらえ刃)付タイプ

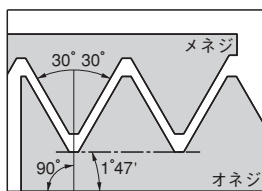

NPT (外径ねじ用)



販売単位：5個

形状	型番	用途		寸法(mm)					PVDコーティング			超微粒子超硬
		ピッチ	山数	d	l	r	x	y	IC808	IC908	IC1007	
	16ER 27 NPT	—	27.0	9.525	16	0.04	0.7	0.8		●		
	16ER 18 NPT	—	18.0	9.525	16	0.06	0.8	1.0		●		
	16ER 14 NPT	—	14.0	9.525	16	0.07	0.9	1.2		●		
	16ER 11.5 NPT	—	11.5	9.525	16	0.09	1.1	1.5		●		
	16ER 8 NPT	—	8.0	9.525	16	0.12	1.3	1.8		○		
	16ERB 18 NPT	—	18.0	9.525	16	0.06	0.8	1.0		○		
	16ERB 14 NPT	—	14.0	9.525	16	0.07	0.9	1.2		○		
	16ERB 11.5 NPT	—	11.5	9.525	16	0.09	1.1	1.5		○		
	16ERB 8 NPT	—	8.0	9.525	16	0.12	1.3	1.8		○		
	16ERM 18 NPT	—	18.0	9.525	16	0.05	0.8	1.0	▲	●		
	16ERM 14 NPT	—	14.0	9.525	16	0.05	0.9	1.2	▲	●	▲	
	16ERM 11.5 NPT	—	11.5	9.525	16	0.09	1.1	1.5		●	▲	
	16ERM 8 NPT	—	8.0	9.525	16	0.12	1.3	1.8	▲	●		

NPT (内径ねじ用)

販売単位：5個

形状	型番	用途		寸法(mm)					PVDコーティング			超微粒子超硬
		ピッチ	山数	d	l	r	x	y	IC808	IC908	IC1007	
	11IR 27 NPT	—	27.0	6.350	11	0.04	0.7	0.8				
	11IR 18 NPT	—	18.0	6.350	11	0.06	0.8	1.0		●		
	11IR 14 NPT	—	14.0	6.350	11	0.07	0.8	1.0		●		
	16IR 14 NPT	—	14.0	9.525	16	0.07	0.9	1.2		●		
	16IR 11.5 NPT	—	11.5	9.525	16	0.09	1.1	1.5		●		
	16IR 8 NPT	—	8.0	9.525	16	0.12	1.3	1.8		○		
	11IRB 18 NPT	—	18.0	6.350	11	0.00	0.8	0.9		▲		
	16IRB 14 NPT	—	14.0	9.525	16	0.07	0.9	1.2		○		
	16IRB 11.5 NPT	—	11.5	9.525	16	0.09	1.1	1.5		○		
	16IRB 8 NPT	—	8.0	9.525	16	0.12	1.2	1.8		○		
	16IRM 14 NPT	—	14.0	9.525	16	0.05	0.9	1.2	▲	●	▲	
	16IRM 11.5 NPT	—	11.5	9.525	16	0.09	1.1	1.5	▲	●	▲	
	16IRM 8 NPT	—	8.0	9.525	16	0.12	1.3	1.8	▲	●	▲	

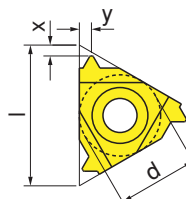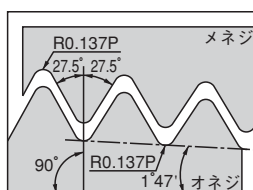

BSPT (外径ねじ用<ブリティッシュ標準管用テーパねじ>仕上刃付き)

販売単位：5個

形状	型番	用途		寸法(mm)					PVDコーティング			超微粒子超硬
		ピッチ	山数	d	l	r	x	y	IC808	IC908	IC1007	
	16ER 28 BSPT	—	28	9.525	16	0.11	0.6	0.6		●		
	16ER 19 BSPT	—	19	9.525	16	0.16	0.8	0.9		●		
	16ER 14 BSPT	—	14	9.525	16	0.21	1.0	1.2		●		
	16ER 11 BSPT	—	11	9.525	16	0.28	1.1	1.5		●		
	16ERB 14 BSPT	—	14	9.525	16	0.21	1.0	1.2		●		
	16ERB 11 BSPT	—	11	9.525	16	0.28	1.1	1.5		●		
	16ERM 14 BSPT	—	14	9.525	16	0.21	1.0	1.2	▲	●	▲	
	16ERM 11 BSPT	—	11	9.525	16	0.28	1.1	1.5		●	▲	

BSPT (内径ねじ用<ブリティッシュ標準管用テーパねじ>仕上刃付き)

販売単位：5個

形状	型番	用途		寸法(mm)					PVDコーティング			超微粒子超硬
		ピッチ	山数	d	l	r	x	y	IC808	IC908	IC1007	
	11IR 19 BSPT	—	19	6.350	11	0.16	0.8	0.9		●		
	11IR 14 BSPT	—	14	6.350	11	0.21	0.9	1.0		●		
	16IR 19 BSPT	—	19	9.525	16	0.16	0.8	0.9				
	16IR 14 BSPT	—	14	9.525	16	0.21	1.0	1.2		●		
	16IR 11 BSPT	—	11	9.525	16	0.28	1.1	1.5		●		
	11IRB 19 BSPT	—	19	6.350	11	0.00	0.8	0.9		▲		
	16IRB 14 BSPT	—	14	9.525	16	0.21	1.0	1.2		●		
	16IRB 11 BSPT	—	11	9.525	16	0.28	1.1	1.5		●		
	16IRM 14 BSPT	—	14	9.525	16	0.21	1.0	1.2	▲	●	▲	
	16IRM 11 BSPT	—	11	9.525	16	0.28	1.1	1.5	▲	●	▲	