

ASD□L Selector Switches (Lever Operator)


Package Quantity: 1

Shape	Lever Operator ASD□L												
90° 2-position	Contact Configuration					Maintained 	Spring Return from Right 	Spring Return from Left 					
	Contact	Contact Block		Operator Position				Contact Block		Operator Position			
		Mounting Position	Contact	1	2		Mounting Position	Contact	1	2			
	1NO (10)	①	NO		●		ASD2L10N	ASD21L10N	①	NO	●		ASD22L10N
		②	—	Dummy Block					②	—	—		
	1NO-1NC (11)	①	NO		●		ASD2L11N	ASD21L11N	①	NO	●		ASD22L11N
		②	NC	●					②	NC		●	
	2NO (20)	①	NO		●		ASD2L20N	ASD21L20N	①	NO	●		ASD22L20N
		②	NO		●				②	NO	●		
	2NO-2NC (22)	①	NO		●		ASD2L22N	ASD21L22N	①	NO	●		ASD22L22N
		②	NC	●					②	NC		●	
		③	NO		●				③	NO	●		
		④	NC	●					④	NC		●	
45° 3-position	Contact Configuration					Maintained 	Spring Return from Right 	Spring Return from Left 			Spring Return Two-way 		
	Contact	Contact Block		Operator Position				1 0 2					
		Mounting Position	Contact	1	2								
	2NO (20)	①	NO	●			ASD3L20N	ASD31L20N	ASD32L20N			ASD33L20N	
		②	NO			●							
	2NC (02)	①	NC		●		ASD3L02N	ASD31L02N	ASD32L02N			ASD33L02N	
		②	NC	●									
	2NO-2NC (22)	①	NO	●			ASD3L22N	ASD31L22N	ASD32L22N			ASD33L22N	
		②	NO			●							
		③	NC		●								
		④	NC	●									
	4NO (40)	①	NO	●			ASD3L40N	ASD31L40N	ASD32L40N			ASD33L40N	
		②	NO			●							
		③	NO	●									
		④	NO			●							
	4NC (04)	①	NC		●		ASD3L04N	ASD31L04N	ASD32L04N			ASD33L04N	
		②	NC	●									
		③	NC		●								
		④	NC	●									
	☆ 3S	①	NO	●			ASD3L3SN-243☆	—	—			—	
		②	NO			●							
		③	NC		●								
		④	—	Dummy Block									

- Lever: Black
- Round bezel (metal): Chrome-plated
- Selector switches with 1 or 3 contact blocks have a dummy block.
- Knob operator can be installed at every 45 degrees intervals in addition to the positions shown in the above table.


- Turn the operator to each position accurately.
- Selector switches with ☆ have a half contact operating current (load switching current value). Rated insulation voltage and rated current remain the same.
- See B-308 for gold-plated silver contacts.
- See B-312 for bottom view.

Contact Block Mounting Position

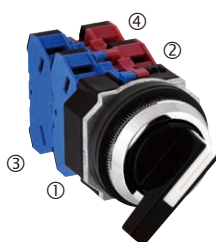

Dimensions

All dimensions in mm.

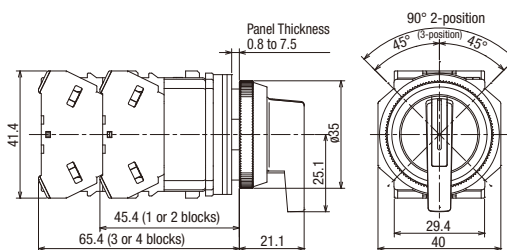

Terminal Screws: M3.5

Terminal cover: integrated

Download catalogs and CAD from <http://asia.idec.com/downloads>