



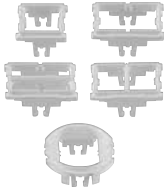
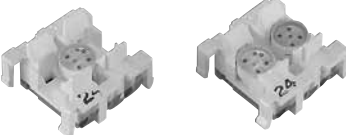
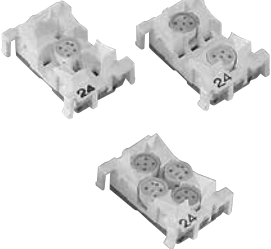


MA Series Maintenance Parts

Maintenance Parts

Name & Shape	Specifications		Part No.	Ordering No.	Package Quantity	Remarks
Color Screen (Acrylic) 	For MA2 Square	Full (11.5H × 11.5W × 1.1t)	MA9Z-P21 *	MA9Z-P21 * PN05	5	<ul style="list-style-type: none"> Specify a color code in place of * in the Ordering No. A (Amber), C (Clear), R (Red), S (Blue)
	For MA3 Rectangular	Full (11.5H × 17.5W × 1.1t)	MA9Z-P31 *	MA9Z-P31 * PN05	5	
		Long Two-way Split (5.7H × 17.5W × 1.1t)	MA9Z-P32 *	MA9Z-P32 * PN05	5	<ul style="list-style-type: none"> Only C (Clear), G (Green), and R (Red) are available.
		Short Two-way Split (11.5H × 8.7W × 1.1t)	MA9Z-P33 *	MA9Z-P33 * PN05	5	
	For MA8 Round	Full (ϕ 17.2 × 1.1t)	MA9Z-P81 *	MA9Z-P81 * PN05	5	<ul style="list-style-type: none"> A (Amber), C (Clear), G (Green), R (Red), S (Blue), Y (Yellow)
Marking Plate (Acrylic) 	For MA2 Square	11.5H × 11.5W × 1.1t	MA9Z-P21W	MA9Z-P21WPN05	5	<ul style="list-style-type: none"> No difference between both sides of the marking plate.
	For MA3 Rectangular	11.5H × 17.5W × 1.1t	MA9Z-P31W	MA9Z-P31WPN05	5	
	For MA8 Round	ϕ 17.2 × 1.1t	MA9Z-P81W	MA9Z-P81WPN05	5	
Lens (Polycarbonate) 	For MA2 Square		MA9Z-L2	MA9Z-L2PN05	5	<ul style="list-style-type: none"> The lens is transparent.
	For MA3 Rectangular		MA9Z-L3	MA9Z-L3PN05	5	
	For MA8 Round		MA9Z-L8	MA9Z-L8PN05	5	
Button (Polyarylate) 	For MA2 Square		MA9Z-B2 *	MA9Z-B2 * PN05	5	<ul style="list-style-type: none"> Specify a color code in place of * in the Ordering No. B (Black), G (Green), R (Red), S (Blue), W (White), Y (Yellow)
	For MA3 Rectangular		MA9Z-B3 *	MA9Z-B3 * PN05	5	
	For MA8 Round		MA9Z-B8 *	MA9Z-B8 * PN05	5	
Lens Holder (Polyarylate) 	For MA2 Square	Full	MA9Z-LH21	MA9Z-LH21PN05	5	
	For MA3 Rectangular	Full	MA9Z-LH31	MA9Z-LH31PN05	5	
		Long Two-way Split (with light barrier)	MA9Z-LH32	MA9Z-LH32PN05	5	
		Short Two-way Split (with light barrier)	MA9Z-LH33	MA9Z-LH33PN05	5	
	For MA8 Round	Full	MA9Z-LH81	MA9Z-LH81PN05	5	

Maintenance Parts (LED Unit)

Name & Shape	Specifications	Operational Voltage	Part No.	Remarks	
MA2 Square / MA8 Round 	One-color	24V AC/DC \pm 5%	MA9Z-2D41N- *	<ul style="list-style-type: none"> Specify a color code in place of * in the Ordering No. A (Amber), G (Green), PW (Pure White), R (Red), S (Blue), W (White) Use a PW (pure white) LED unit for yellow illumination. 	
		12V AC/DC \pm 5%	MA9Z-2D31N- *		
		5V DC \pm 5%	MA9Z-2D11N- *		
MA3 Rectangular 	Two-color Alternate (Except for MA8)	24V AC/DC \pm 5%	MA9Z-2D44N-RG	<ul style="list-style-type: none"> Blue (S) is for One-color only. For color codes of Two-way Split type, WW, RG, RW and GW are available. Package quantity: 1 	
		One-color	24V AC/DC \pm 5%		MA9Z-3D41N- *
			12V AC/DC \pm 5%		MA9Z-3D31N- *
	5V DC \pm 5%		MA9Z-3D11N- *		
	Short Two-way Split	24V AC/DC \pm 5%	MA9Z-3D43N- **		
		12V AC/DC \pm 5%	MA9Z-3D33N- **		
		5V DC \pm 5%	MA9Z-3D13N- **		
	Long Two-way Split	24V AC/DC \pm 5%	MA9Z-3D42N- **		
		12V AC/DC \pm 5%	MA9Z-3D32N- **		
		5V DC \pm 5%	MA9Z-3D12N- **		
Two-color Alternate	24V AC/DC \pm 5%	MA9Z-3D44N-RG			