



コネクタ(おす)
MALE CONNECTOR

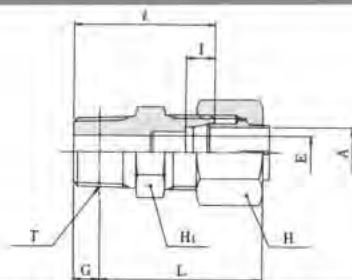

Unit : mm

継手の呼び Part No.	Tube OD A	(R) T	Minimum Opening E	Gauge Length G	六角対辺 Hex.		I	ℓ	Approx. L (約)	重量 (kg)
					H ₁	H				
KCT06-010CE	6	1/8	4.5	3.97	12	12	5.5	22.5	27.8	0.017
KCT06-020CE	6	1/4	4.5	6.01	14	12	5.5	26.5	29.8	0.024
KCT06-030CE	6	3/8	4.5	6.35	17	12	5.5	29	31.9	0.039
KCT08-010CE	8	1/8	4.5	3.97	12	14	5.5	23	29	0.019
KCT08-020CE	8	1/4	6	6.01	14	14	5.5	27	31	0.026
KCT08-030CE	8	3/8	6	6.35	17	14	5.5	29.5	33.1	0.042
KCT10-020CE	10	1/4	7	6.01	14	17	5.5	28	32	0.032
KCT10-030CE	10	3/8	8	6.35	17	17	5.5	30	33.7	0.044
KCT12-020CE	12	1/4	7	6.01	17	19	6	29	33	0.038
KCT12-030CE	12	3/8	9	6.35	17	19	6	30	33.7	0.043
KCT12-040CE	12	1/2	10	8.16	22	19	6	36	37.8	0.078
KCT16-030CE	16	3/8	9	6.35	22	27	8	33.5	39.8	0.092
KCT16-040CE	16	1/2	12	8.16	22	27	8	37.5	41.9	0.105
KCT20-040CE	20	1/2	12	8.16	27	30	8	37.5	43.6	0.116
KCT20-060CE	20	3/4	16	9.53	27	30	8	39.5	44.3	0.140
KCT25-060CE	25	3/4	16	9.53	32	36	9	42.5	47.8	0.189
KCT25-080CE	25	1	20	10.39	36	36	9	46.5	50.9	0.249
KCT30-060CE	30	3/4	16	9.53	36	41	9	44.5	50.3	0.253
KCT30-080CE	30	1	22	10.39	36	41	9	47.5	52.4	0.262
KCT30-100CE	30	1 1/4	26	12.7	46	41	9	51	53.6	0.402

隔壁締付コネクタ
(おす)

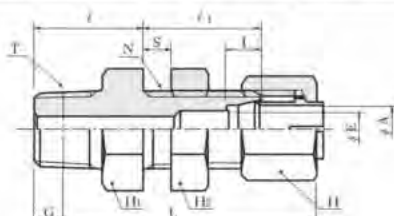

Unit : mm

継手の呼び Part No.	Tube OD A	(R) T	E	Gauge Length G	六角対辺 Hex.			I	ℓ	ℓ ₁	Approx. L (約)	N	Max. S	重量 (kg)
					H ₁	H ₂	H							
KSC06-010CE	6	1/8	4	3.97	14	14	12	5.5	15	26	46.3	M10×1	13	0.033
KSC06-020CE	6	1/4	4.5	6.01	14	14	12	5.5	19	26	48.3	M10×1	13	0.038
KSC08-010CE	8	1/8	4	3.97	17	17	14	5.5	16	27.5	49.5	M12×1	13	0.051
KSC08-020CE	8	1/4	6	6.01	17	17	14	5.5	20	27.5	51.5	M12×1	13	0.052
KSC10-020CE	10	1/4	7	6.01	19	19	17	5.5	21	29	54	M14×1	13	0.066
KSC10-030CE	10	3/8	8	6.35	19	19	17	5.5	22	29	54.7	M14×1	13	0.074
KSC12-020CE	12	1/4	7	6.01	22	22	19	6	21	29	54	M16×1	13	0.094
KSC12-030CE	12	3/8	9	6.35	22	22	19	6	22	29	54.7	M16×1	13	0.088
KSC16-030CE	16	3/8	9	6.35	27	27	27	8	23	34	63.3	M22×1.5	15	0.163
KSC16-040CE	16	1/2	12	8.16	27	27	27	8	27	34	65.4	M22×1.5	15	0.176
KSC20-040CE	20	1/2	12	8.16	32	32	30	8	29	36	71.1	M26×1.5	15	0.243
KSC20-060CE	20	3/4	16	9.53	32	32	30	8	31	36	71.8	M26×1.5	15	0.251
KSC25-060CE	25	3/4	16	9.53	36	36	36	9	32	37.5	74.8	M32×1.5	15	0.357
KSC25-080CE	25	1	20	10.39	36	36	36	9	35	37.5	76.9	M32×1.5	15	0.420
KSC30-060CE	30	3/4	16	9.53	41	41	41	9	32.5	39	77.3	M36×1.5	15	0.430
KSC30-080CE	30	1	22	10.39	41	41	41	9	35.5	39	79.4	M36×1.5	15	0.457
KSC30-100CE	30	1 1/4	26	12.7	46	41	41	9	39	39	80.6	M36×1.5	15	0.554

△ 注意：この形式の継手は隔壁貫通を目的としたので、強振動の発生する箇所、或いは接続ホースの圧力変動が大きい箇所では配管クランプ等、振動対策（継手に掛かる発生応力を軽減するため）が必要です。