

For compressors

Flat Type  
Plastic

FEATURES

- Uniform distribution resulting from the unique flat design.
- Made of high chemical/heat resistant PPS.
- Designed to have minimal noise level.

Flat Type



【Spray pattern】



121 mm wide  
Broad type

- ▶ Powerful air nozzle dramatically multiplies the supplied air volume.
- ▶ Spray width is three times broader than our conventional flat type (42 mm wide).



Material: PPS  
Mass: 62 g  
Max. air pressure: 0.7 MPa (100 psi)  
Max. allowable temperature: 120°C (240°F)

■ Dimensions

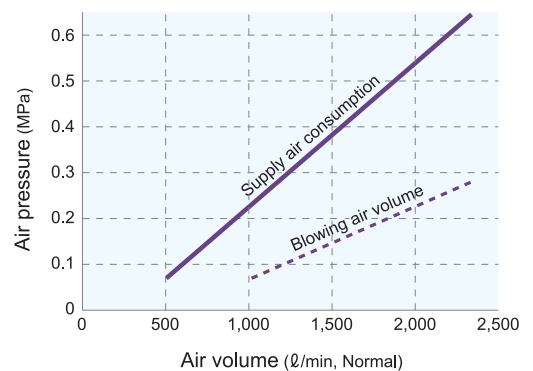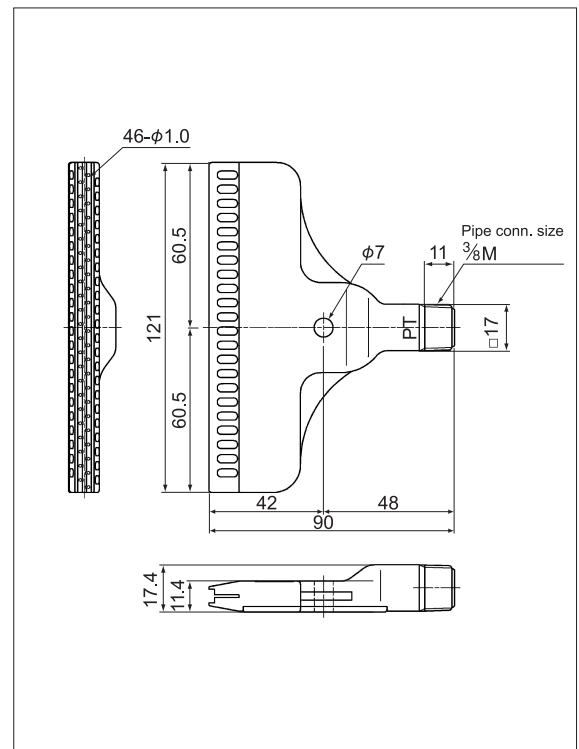

How to order

Please inquire or order using this product code.

**3/8M(PT) TF-F 121-46-010 PPS**

Thread type  
■ (PT)  
■ (NPT)