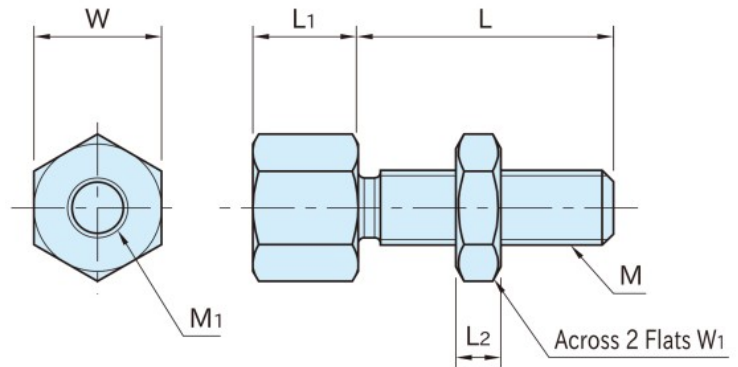


**BJ332****JACK SCREWS**

Body
Steel (S45C)
Black oxide finish

Part Number	L	L1	W	M1	M	W1	L2	Load Capacity (N)	Weight (g)
<b>BJ332-08020</b>	20	10	13	M 6×1 6 deep	M 8×1.25	13	5	2,600	20
<b>BJ332-08030</b>	30								25
<b>BJ332-10024</b>	24	14	17	M 8×1.25 8 deep	M10×1.5	17	6	3,900	45
<b>BJ332-10034</b>	34								50
<b>BJ332-12033</b>	33	18	22	M10×1.5 10 deep	M12×1.75	22	7	5,900	95
<b>BJ332-12048</b>	48								110
<b>BJ332-16040</b>	40	22	27	M12×1.75 12 deep	M16×2	27	10	11,000	185
<b>BJ332-16055</b>	55								210
<b>BJ332-20050</b>	50	26	30	M16×2 16 deep	M20×2.5	30	12	18,000	300
<b>BJ332-20070</b>	70								340

**How To Use**

Adjustable support that accepts a tip on top.

