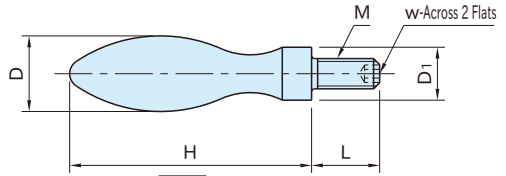
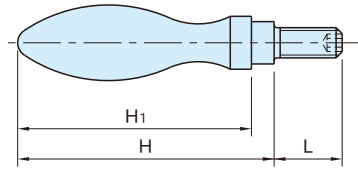


ALG**ALUMINUM HANDLES****ALG**
(Fixed)**ALG-R**
(Revolving)**ALG**
(Fixed)**ALG-R**
(Revolving)

Type	Body	Stud
ALG	Aluminum alloy (AC4B) Buffed finish	Steel(SUM22L) Black oxide finish
ALG-R	Aluminum alloy (AC4B) Buffed finish	Steel(SUM22L) Zinc plated

ALG (Fixed)

Part Number	D	D ₁	H	M	L	w	Weight (g)
ALG16	16	10	50	M 6×1	11	3	20
ALG20	20	13	64	M 8×1.25	13	4	35
ALG25	25	16	80	M10×1.5	14	5	75
ALG32	32	20	100	M12×1.75	21	6	130

ALG-R (Revolving)

Part Number	D	D ₁	H	H ₁	M	L	w	Weight (g)
ALG16R	16	10	54.5	49	M 6×1	11	3	35
ALG20R	20	13	67	61	M 8×1.25	13	4	55
ALG25R	25	16	83	75	M10×1.5	14	5	95
ALG32R	32	20	105.5	95	M12×1.75	21	6	195

Features

A hex. wrench hole is provided at the end of the stud, for installation.

Notes

Dimensions are subject to slight variations due to buffed finish.