


**BJ370****PNEUMATIC WORK SUPPORTS**

Body	Piston	Locking Shaft
Aluminum (A5052) Anodized	SK95 steel Quenched & tempered Black oxide finished	S45C steel Electroless nickel plated

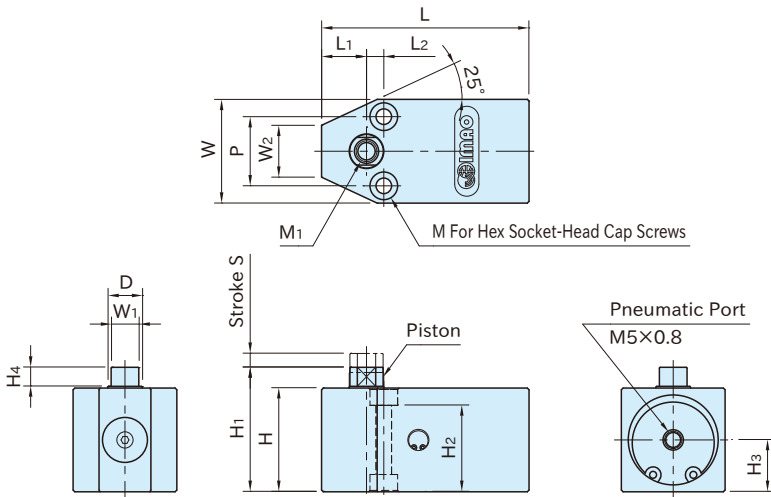

Part Number	H	H <sub>1</sub>	S	M <sub>1</sub>	D	L	W	M	H <sub>2</sub>	P	H <sub>3</sub>	W <sub>1</sub>	H <sub>4</sub>
<b>BJ370-05001</b>	25	30	3	M5×0.8 Depth10	8	50	25	M3	21	16	12.5	7	4.5
<b>BJ370-06001</b>	30	36	4	M6×1.0 Depth12	10	60	30	M4	25	20	15	8	5.5

Part Number	L <sub>1</sub>	L <sub>2</sub>	W <sub>2</sub>	Operating Air Pressure (MPa)	Support Capacity (N)	Piston Spring Force (N)	Weight (g)
<b>BJ370-05001</b>	11	4	12	0.3~1.0	300~500	1~1.9	92
<b>BJ370-06001</b>	13	5	15	0.3~1.0	500~700	1~2.2	165