


# BJ737-A

# SWIVEL HEAD SCREWS, Type A

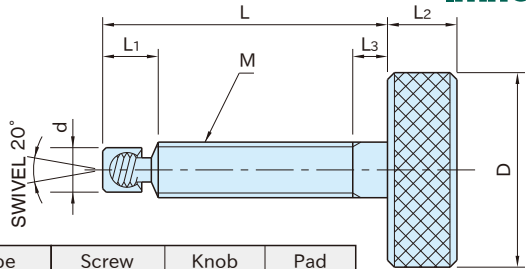

Type	Screw	Knob	Pad
<b>BJ737</b> -06	SCM435 steel Quenched & tempered Black oxide finished	S45C steel Black oxide finished	SUM24L steel Black oxide finished
<b>BJ737</b> -08			
<b>BJ737</b> -10			
<b>BJ737</b> -12	SCM435 steel Quenched & tempered Black oxide finished	S45C steel Black oxide finished	SUM24L steel Black oxide finished
<b>BJ737</b> -16			

Part Number	M	L	d	D	L <sub>1</sub>	L <sub>2</sub>	L <sub>3</sub>	Weight (g)
<b>BJ737-06025A</b>	M 6×1	25	4.8	25	7	8	3	40
<b>BJ737-06050A</b>		50						45
<b>BJ737-06075A</b>		75						50
<b>BJ737-08025A</b>	M 8×1.25	25	6.4	29	9	10	5	60
<b>BJ737-08050A</b>		50						70
<b>BJ737-08075A</b>		75						80
<b>BJ737-10050A</b>	M10×1.5	50	7.6	32	10	11	5	100
<b>BJ737-10075A</b>		75						115
<b>BJ737-10100A</b>		100						130
<b>BJ737-12050A</b>	M12×1.75	50	9.9	32	12	13	-	125
<b>BJ737-12075A</b>		75						145
<b>BJ737-12100A</b>		100						170
<b>BJ737-16050A</b>	M16×2	50	12.7	32	16	13	-	155
<b>BJ737-16075A</b>		75						195
<b>BJ737-16100A</b>		100						235
<b>BJ737-16125A</b>		125						275

### Note

Feet have lefthand threads to positively prevent backout when turning the screw counterclockwise.

### How To Use

