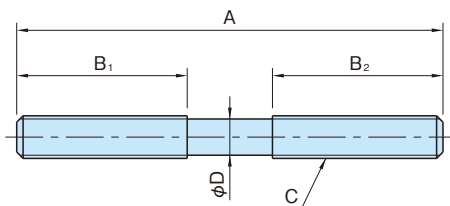


BJ745**STUDS**

Type	Body
BJ745 -08~20	Steel (SCM435) Quenched and tempered (HRC33 - 39) Black oxide finish
BJ745 -24	Steel (SCM435) Quenched and tempered (HRC23 - 34) Black oxide finish

Part Number	A	B ₁	B ₂	C	D	Weight (g)
BJ745-08050	50	20	20	M 8×1.25	7.1	20
BJ745-08063	63	25	25			25
BJ745-08080	80	32	32			35
BJ745-08100	100					40
BJ745-08125	125					45
BJ745-08160	160					55
BJ745-10050	50	20	20	M10×1.5	8.9	30
BJ745-10063	63	25	25			40
BJ745-10080	80	32	32			45
BJ745-10100	100	40	40			55
BJ745-10125	125					70
BJ745-10160	160					90
BJ745-10200	200					110
BJ745-12050	50	20	20	M12×1.75	10.7	40
BJ745-12063	63	25	25			50
BJ745-12080	80	32	32			65
BJ745-12100	100	40	40			80
BJ745-12125	125					100
BJ745-12160	160					125
BJ745-12200	200					160

※Some items are not RoHS-compliant. Contact us at info@imao.jp for the updated information.